



**Hoffman**

### DESCRIPTION

The Hoffman A Series Small NEMA 1 enclosures house controls and instruments in areas which do not require oil-tight and dust-tight ratings.

### FEATURES

- Removable doors with butt hinges
- Mounting holes on back of enclosure
- Easy operation of flush latch with a screwdriver or coin
- Weldnuts provided for mounting optional panels
- ANSI 61 gray polyester-powder coating inside and out over phosphorized surfaces
- Optional steel panels with white finish
- UL File #E27567
- CSA File #LL42184, RoHs
- One-year warranty




Nema 1 Small



### DIMENSIONS

in  
(cm)

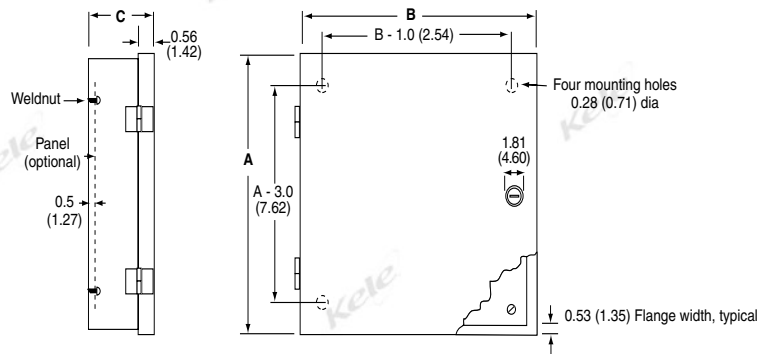

### ORDERING INFORMATION

ENCLOSURE MODEL†	DIMENSIONS A x B x C in (cm)	BODY GAUGE	WEIGHT lb (Kg)	SOLID PANEL* MODEL	DIMENSIONS H x W in (cm)	GAUGE	WEIGHT lb (Kg)
A-6N64	6 x 6 x 4 (15 x 15 x 10)	16	4.0 (1.8)	A-6N6P	4.25 x 4.25 (11 x 10)	14	0.5 (0.2)
A-8N64	8 x 6 x 4 (20 x 15 x 10)	16	5.0 (2.3)	A-8N6P	6.25 x 4.25 (16 x 11)	14	0.75 (0.3)
A-8N84	8 x 8 x 4 (20 x 20 x 10)	16	6.0 (2.7)	A-8N8P	6.25 x 6.25 (16 x 16)	14	1.0 (0.5)
A-10N84	10 x 8 x 4 (25 x 20 x 10)	16	6.5 (3.0)	A-10N8P	8.25 x 6.25 (21 x 16)	14	1.0 (0.5)
A-10N104	10 x 10 x 4 (25 x 25 x 10)	16	7.5 (3.4)	A-10N10P	8.25 x 8.25 (21 x 21)	14	1.5 (0.7)
A-12N104	12 x 10 x 4 (30 x 25 x 10)	16	9.0 (4.1)	A-12N10P	10.25 x 8.25 (26 x 21)	14	2.0 (0.9)
A-12N124	12 x 12 x 4 (30 x 30 x 10)	16	10.0 (4.6)	A-12N12P	10.25 x 10.25 (26 x 26)	14	2.5 (1.1)
A-14N124	14 x 12 x 4 (36 x 30 x 10)	16	11.0 (5.0)	A-14N12P	12.25 x 10.25 (31 x 26)	14	3.0 (1.4)
A-8N86	8 x 8 x 6 (20 x 20 x 15)	16	6.0 (2.7)	A-8N8P	6.25 x 6.25 (16 x 16)	14	1.0 (0.5)
A-10N86	10 x 8 x 6 (25 x 20 x 15)	16	8.0 (3.6)	A-10N8P	8.25 x 6.25 (21 x 16)	14	1.0 (0.5)
A-10N106	10 x 10 x 6 (25 x 25 x 15)	16	9.0 (4.1)	A-10N10P	8.25 x 8.25 (21 x 21)	14	1.5 (0.7)
A-12N106	12 x 10 x 6 (30 x 25 x 15)	16	10.0 (4.6)	A-12N10P	10.25 x 8.25 (26 x 21)	14	2.0 (0.9)
A-12N126	12 x 12 x 6 (30 x 30 x 15)	16	12.0 (5.5)	A-12N12P	10.25 x 10.25 (26 x 26)	14	2.5 (1.1)
A-14N126	14 x 12 x 6 (36 x 30 x 15)	16	13.0 (5.9)	A-14N12P	12.25 x 10.25 (31 x 26)	14	3.0 (1.4)
A-16N126	16 x 12 x 6 (41 x 30 x 15)	16	14.0 (6.4)	A-16N12P	14.25 x 10.25 (36 x 26)	14	3.5 (1.6)
A-20N126	20 x 12 x 6 (51 x 35 x 15)	16	17.0 (7.8)	A-20N12P	18.25 x 10.25 (46 x 36)	14	4.0 (1.8)
A-12N128	12 x 12 x 8 (30 x 30 x 20)	16	14.0 (6.4)	A-12N12P	10.25 x 10.25 (26 x 26)	14	2.5 (1.1)
A-14N128	14 x 12 x 8 (36 x 30 x 20)	16	15.0 (6.8)	A-14N12P	12.25 x 10.25 (31 x 26)	14	3.0 (1.4)

† Add P to the end of the model number to order optional perf panel.  
See Accessories page for locks, latches, heaters, fans, and ventilation kits.  
\* Order panels separately