

WALL MASTER STATION

STANDARD



when **communication** is **critical**

FEATURES

- Fully equipped analogue master station with free access to all extensions and features
- Conformity with the latest STENTOFON station design with rugged front plate in anodized brushed aluminium and silicone rubber keypad
- Private / Open switch
- Built-in 63 Ohm / 1 W loudspeaker
- Adjustable loudspeaker volume
- Excellent sound quality

DESCRIPTION

The 7040 station is a fully equipped analogue master station with free access to all extensions and features. This master station is designed for both flush and surface mounting; in- and on-wall back boxes are available for this purpose. The station can also be flush mounted into a desk.

Typical application areas are hospitals, airports, stores and warehouses, factory shop floors and nurseries. A modular RJ45 jack plug on the station facilitates quick and easy connection. A CAT3 or higher or a 2-pair 0.5 mm² twisted telephone cable is required between the exchange and the station. The maximum distance is 1.4 km with 0.5 mm² cable. Longer distances are possible by using heavier wires. The station is equipped with a sensitive electret microphone and a 1 W loudspeaker. The loudspeaker volume is easily adjustable on the station front.




SPECIFICATIONS

Operation Voltage	Powered from exchange
Cable Requirements	2 pair twisted cable, 0.5 mm ² / 24 AWG - 4,600 feet
Temperature Range	0°C to +40°C
Humidity Range	10% - 85% RH (non condensing)
Dimensions: (WxHxD)	4.9 x 11 x 2.1 inch.
Finish	Anodized brushed aluminium
Loudspeaker Output	1 W
Loudspeaker Sound Pressure Level	75 dB @ 1 KHz, 2.5 VRMS on ab-wire, 100 m 0.5 mm ² cable
Connector Type	RJ45 Modular Jack
Indicator	LED (red)


ORDER NUMBER	DESCRIPTION	SHIP WEIGHT
1007040000	Wall Master Station, Standard	1.3 lb.
1000602000	Flush mount back box	1.3 lb.
6031	Surface mount back box	1.3 lb.

WALL MASTER STATION STANDARD

INSTALLATION

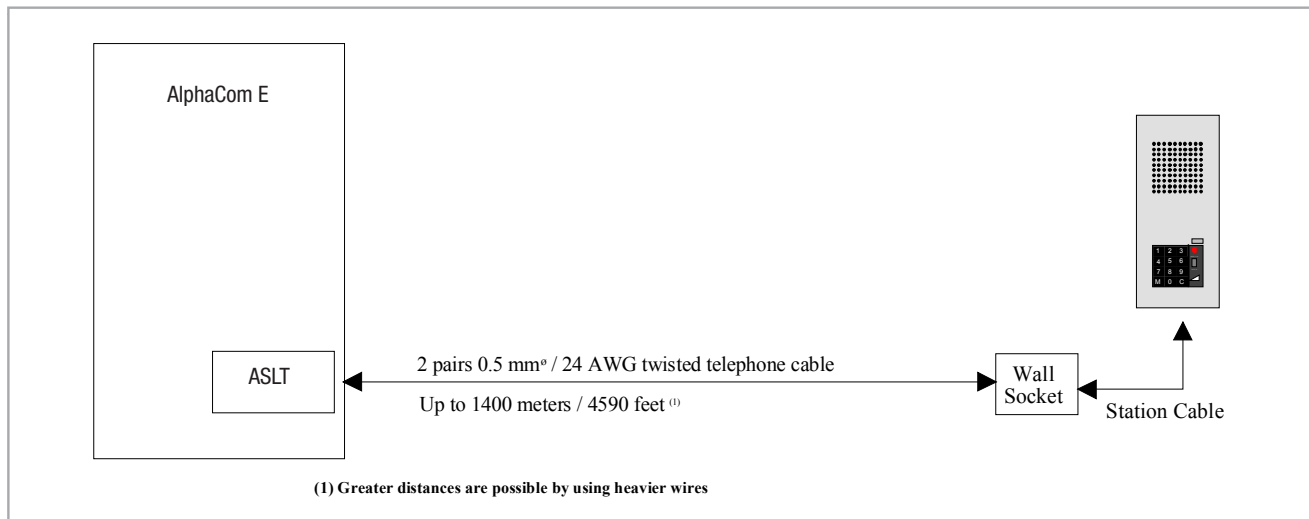

DRAWING WALL BOX

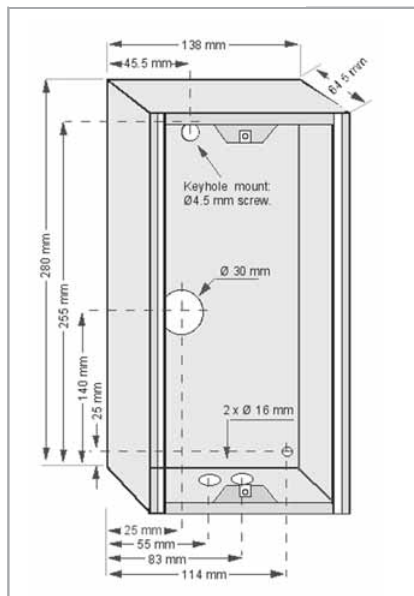

DRAWING FLUSH MOUNT BOX

