

WALL MASTER STATION

DISPLAY



when communication is critical

FEATURES

- Fully equipped analogue master station with free access to all extensions and features
- Eight freely programmable single touch keys
- 2 x 16 character alphanumeric display
- Conformity with the latest STENTOFON station design with rugged front plate in anodized brushed aluminium and silicone rubber keypad
- Private / Open switch
- Built-in 63 Ohm / 1 W loudspeaker
- Adjustable loudspeaker volume
- Excellent sound quality

DESCRIPTION

The 7042 station is a fully equipped analogue master station with free access to all extensions and features. The station includes programmable single touch keys and a 2 x 16 character alphanumeric display providing caller identification, on-line help and a directory service amongst other features. This master station is designed for both flush and surface mounting; in- and on-wall back boxes are available for this purpose. The station can also be flush mounted into a desk.

Typical application areas are hospitals, airports, stores and warehouses, factory shop floors and nurseries. A modular jack plug on the station facilitates quick and easy connection. A CAT3 or higher, or a 2-pair 0.5 mm² twisted telephone cable is required between the exchange and the station. The maximum distance is 1.4 km with 0.5 mm² cable. Longer distances are possible by using heavier wires. The station is equipped with a sensitive electret microphone and a 1 W loudspeaker. The loudspeaker volume is easily adjustable on the station front.



SPECIFICATIONS


Operation Voltage	Powered from exchange
Cable Requirements	2 pair twisted cable, 0.5 mm ² / 24 AWG / 4,600 feet
Temperature Range	0° C to +40° C
Humidity Range	10% - 85% RH (non condensing)
Dimensions: (WxHxD)	4.9 x 11 x 2.1 inch
Finish	Anodized brushed aluminium
Loudspeaker Output	1 W
Loudspeaker Imp	63 Ohm

ORDER NUMBER	DESCRIPTION	SHIP WEIGHT
1007042000	Wall Master Station, Display	1.3 lb.
1000602000	Flush mount back box	1.3 lb.
1006031000	Surface mount back box	2.0 lb.


WALL MASTER STATION DISPLAY

Frequency Range	300 - 5000 Hz
Loudspeaker Sound Pressure Level	75 dB @ 1 KHz, 2.5 VRMS on ab-wire, 100 m 0.5 mm ² cable
Connector Type	RJ45 Modular Jack
Indicator	LED (red)

INSTALLATION

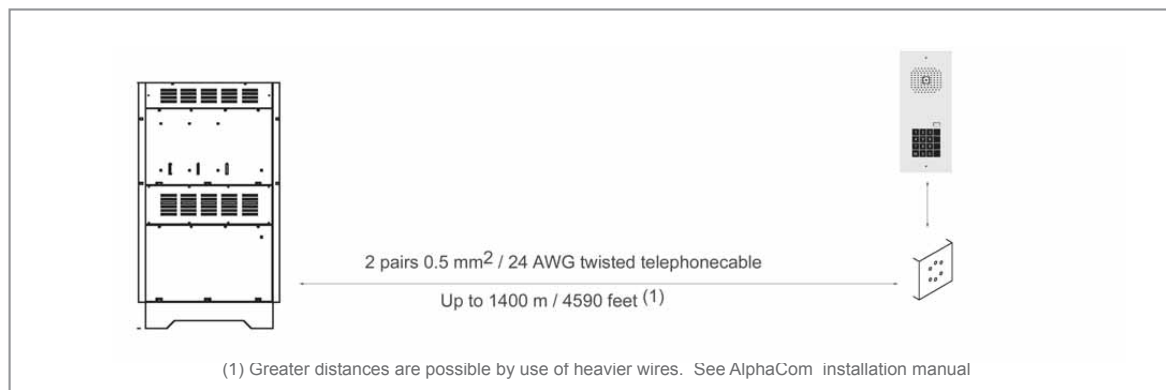

DRAWING ON-WALL BOX

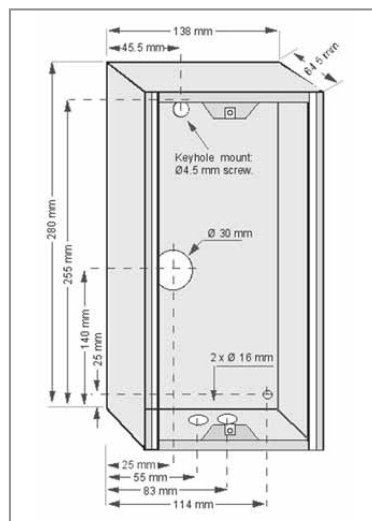

DRAWING FLUSH MOUNT BOX

