

# PANEL FABRICATION

## FUSES

**FLM, FLQ, KLK, GF, K235, 251 SERIES, HRK, HKP-HH**



### DESCRIPTION

**FLM and FLQ Series Midget Fuses** are slow-acting fuses used with 6M30 Series, 6W30 Series, and FB2X Series fuse holders.

### APPLICATION

- *Inductive loads, power supplies, control transformers, and control circuits with high inrush currents*

SPECIFICATIONS / ORDERING INFORMATION		
AMP RATING	250V MODEL	500V MODEL
0.5	FLM-0.5	FLQ-0.5
0.8	FLM-0.8	FLQ-0.8
1.0	FLM-1	FLQ-1
1.25	FLM-1.25	FLQ-1.25
1.5	FLM-1.5	FLQ-1.5
2.0	FLM-2	FLQ-2
2.5	FLM-2.5	FLQ-2.5
3.0	FLM-3	FLQ-3
4.0	FLM-4	FLQ-4
5.0	FLM-5	FLQ-5
7.0	FLM-7	FLQ-7
10.0	FLM-10	FLQ-10
15.0	FLM-15 (125 VAC)	FLQ-15
20.0	FLM-20 (32 VAC)	FLQ-20
30.0	FLM-30 (32 VAC)	FLQ-30
AMP RATING	600V MODEL	
3.0A	KLK-3	



FLM/FLQ/KLK Series




### DESCRIPTION

The **KLK-3 Series** fuses are fast-acting fuses.

### APPLICATION

- *Watt meters, watt transducers, and control circuits without high inrush currents*

### DIMENSIONS

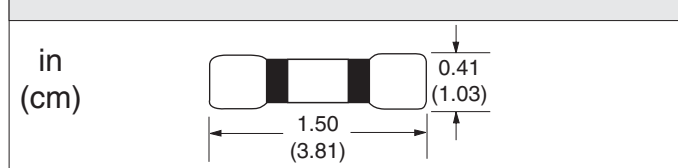

### DESCRIPTION

**GF and K235 Series Glass Fuses** are available in slow-blow and fast-acting models.

### APPLICATION

- *GF Series for use with Model M10/16SFL fuse holder and HRK*
- *K235 Series for use with M4/8 fuse holder and HRK*

SPECIFICATIONS / ORDERING INFORMATION (Order QTY 1 = standard package of 5) Ex. 5 GF-5 = 25 fuses				
AMP RATING	VOLTAGE	FAST-ACTING FUSE	SLOW-BLOW FUSE	FAST-ACTING
0.5	250	GF-0.5	GF-0.5S	K235-0.5
1	250	GF-1	GF-1S	K235-1
1.5	250	GF-1.5	GF-1.5S	K235-1.5
2	250	GF-2	GF-2S	K235-2
2.5	250	GF-2.5	GF-2.5S	K235-2.5
3	250	GF-3	GF-3S	K235-3
5	250	GF-5	GF-5S	K235-5 (125V)
7	250	GF-7	GF-7S	K235-7 (125V)
10	250	GF-10	GF-10S*	K235-10 (125V)
15	250	GF-15*	GF-15S*	
HRK		Inline fuseholder, 32V, 15A, for 1/4" fuses 7/8"-1-1/4"		
HKP-HH		Panel mount fuseholder, 250V, 15A, for 1/4" x 1-1/4" fuses		

\* Ceramic tube fuse




GF, K235 Series

HRK



### DIMENSIONS

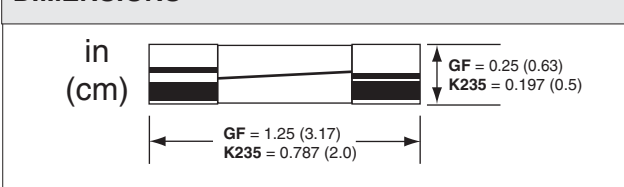

### DESCRIPTION

**251 Series PICO™ Fuses** are fast-acting fuses.

### APPLICATION

- *Printed circuit board fuses*

SPECIFICATIONS / ORDERING INFORMATION (Sold in packs of 10) (Order QTY 1 = PACKAGE of 10)	
AMP RATING	125V MODEL
1/8	#251.125
1/2	#251.500
1	#251001
2	#251002



251 Series



### DIMENSIONS

