



LIGHTING CONTROLS

MANUAL TIME SWITCH 93000 SERIES

DESCRIPTION

The Marktime 93000 Series wall box time switch is a spring wound, manually set time switch for the control of electrical current. Interchangeable with standard toggle switches to turn circuits either off or on at the end of a preset time period, the 93000 Series is ideally suited for new installations or retrofit projects.

FEATURES

- White and ivory plates and knobs included
- Time range from minutes to 12 hours
- Wwo-wire design to fit standard single-gang box
- 20 Amp Resistive & 1 hp Capability
- Optional "Hold" models available



93504C




SPECIFICATIONS

Supply Voltage	125/277VAC, 50/60Hz Not Required to operate	Indicators	None
Operation	Spring return count down timer Manually Twist past mark to desired time, On activation both contacts transfer from normal	Timers	0-(15, 30, 60, 120) minutes or 0-(4, 6, 12) hours
Relay Output Configuration	2-SPST, 1-N.O. and 1-N.C	Operating Temperature	-40 to 120 (-40 to 49)
Contact Current		Operating Humidity	5% to 95% Non-condensing
Resistive	20A @ 125 VAC, 10A @ 277VAC	Wiring Terminations	Terminals, 12 AWG
Ballast	Do not use with Ballasts	Mounting	Vertical, Single gang switch box (not included)
Tungsten	7A Tungsten @ 125 VAC	Color	Plastic plate in Ivory and White included
FAN	1 Hp @ 125 VAC	Enclosure Rating	NEMA 1
Manual Override	Hold on some models	Dimensions	1.8"W x 3.8"H x 1.2"D (4.5 x 9.7 x 3.1 cm) Knob 0.75" from faceplate
Clock Accuracy	± 5% of set time	Weight	0.4 lb (0.18 Kg)
Special Functions		Approvals	UL Listed, File E13151
93351XC	HOLD closed in the "ON" position Full Metal faceplate	Warranty	1 year

11


LIGHTING CONTROLS

WIRING

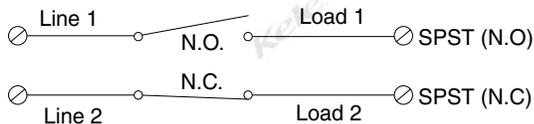

Note: For SPDT operation, install jumper wire from Line 1 terminal to the Line 2 terminal

DIMENSIONS

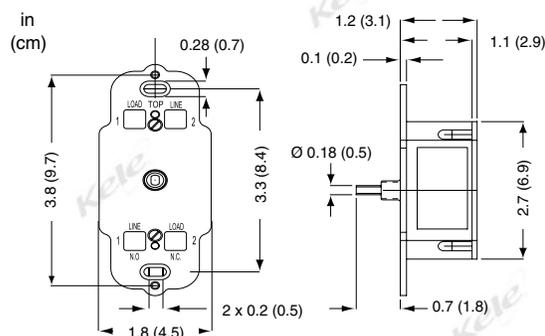

ORDERING INFORMATION

MODEL	DESCRIPTION	MODEL	DESCRIPTION
93501C	0-15 min. timer includes knob and trim plate	93506C	0-12 hr. timer includes knob and trim plate
93502C	0-30 min. timer includes knob and trim plate	93507C	0-4 hr. timer includes knob and trim plate
93503C	0-60 min. timer includes knob and trim plate	93513C	0-60 min. timer with Hold, includes knob and trim plate
93504C	0-120 min. timer includes knob and trim plate	93516C	0-12 hr. timer with Hold, includes knob and trim plate
93505C	0-6 hr. timer includes knob and trim plate		