



### DESCRIPTION

Hoffman **A-LP Series** NEMA 12 enclosures house electrical and pneumatic controls, instruments, and components. These enclosures provide protection from dust, dirt, oil, and water.

### FEATURES


- 16-gauge steel bodies and 14-gauge doors on sizes through 24" x 24", larger sizes all 14 gauge
- Seams continuously welded and ground smooth, no holes or knockouts
- External mounting feet
- Quick and easy operation of door clamps
- Door removable by pulling heavy gauge continuous-hinge pin
- Hasp and staple for padlocking
- Oil-resistant gasket attached with adhesive and steel retaining strips
- Collar studs for mounting optional panels
- White inside with ANSI 61 gray outside finish over phosphatized surfaces
- Optional steel panels with white finish
- UL listed, File #E61977
- CSA certified, File #LR42186



6

ENCLOSURES

### DIMENSIONS

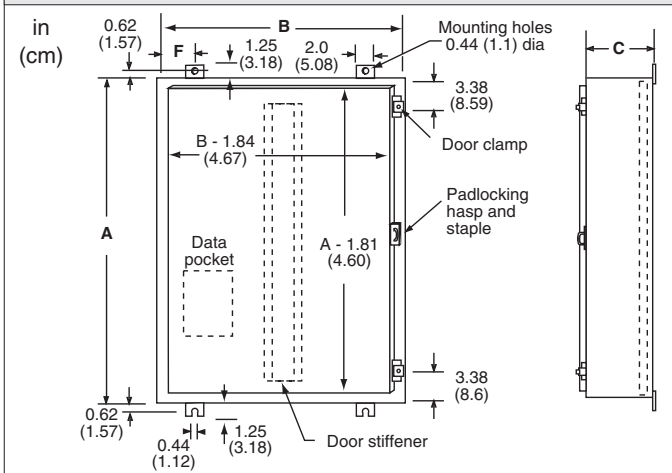

### ORDERING INFORMATION

| ENCLOSURE MODEL | DIMENSIONS in (cm)          |            | WEIGHT lb (kg) | SOLID PANEL* MODEL | DIMENSIONS H x W in (cm) | WEIGHT lb (kg) |
|-----------------|-----------------------------|------------|----------------|--------------------|--------------------------|----------------|
|                 | A x B x C                   | F          |                |                    |                          |                |
| A-161206LP      | 16 x 12 x 6 (41 x 30 x 15)  | 1.25 (3.1) | 17.3 (7.8)     | A-16P12            | 13 x 9 (33 x 23)         | 3.6 (1.6)      |
| A-161606LP      | 16 x 16 x 6 (41 x 41 x 15)  | 3.0 (7.6)  | 21.2 (9.6)     | A-16P16            | 13 x 13 (33 x 33)        | 5.3 (2.4)      |
| A-201606LP      | 20 x 16 x 6 (51 x 41 x 15)  | 3.0 (7.6)  | 25.1 (11.4)    | A-20P16            | 17 x 13 (43 x 33)        | 7.0 (3.2)      |
| A-202006LP      | 20 x 20 x 6 (51 x 51 x 15)  | 3.0 (7.6)  | 29.1 (13.2)    | A-20P20            | 17 x 17 (43 x 43)        | 10.0 (4.5)     |
| A-242006LP      | 24 x 20 x 6 (61 x 51 x 15)  | 3.0 (7.6)  | 34.1 (15.5)    | A-24P20            | 21 x 17 (53 x 43)        | 11.0 (5.0)     |
| A-242406LP      | 24 x 24 x 6 (61 x 61 x 15)  | 3.0 (7.6)  | 39.0 (17.7)    | A-24P24            | 21 x 21 (53 x 53)        | 13.0 (5.9)     |
| A-302406LP      | 30 x 24 x 6 (76 x 61 x 15)  | 3.0 (7.6)  | 52.0 (23.6)    | A-30P24            | 27 x 21 (69 x 53)        | 18.0 (8.2)     |
| A-362406LP      | 36 x 24 x 6 (91 x 61 x 15)  | 3.0 (7.6)  | 62.0 (28.1)    | A-36P24            | 33 x 21 (83 x 53)        | 23.0 (10.4)    |
| A-363006LP      | 36 x 30 x 6 (91 x 76 x 15)  | 3.0 (7.6)  | 75.0 (34.0)    | A-36P30            | 33 x 27 (83 x 69)        | 27.0 (12.2)    |
| A-161208LP      | 16 x 12 x 8 (41 x 30 x 20)  | 1.25 (3.1) | 19.3 (8.8)     | A-16P12            | 13 x 9 (33 x 23)         | 3.6 (1.6)      |
| A-201608LP      | 20 x 16 x 8 (51 x 41 x 20)  | 3.0 (7.6)  | 27.3 (12.4)    | A-20P16            | 17 x 13 (43 x 33)        | 7.0 (3.2)      |
| A-241608LP      | 24 x 16 x 8 (61 x 41 x 20)  | 3.0 (7.6)  | 31.3 (14.2)    | A-24P16            | 21 x 13 (53 x 33)        | 8.7 (3.9)      |
| A-242008LP      | 24 x 20 x 8 (61 x 51 x 20)  | 3.0 (7.6)  | 37.0 (16.8)    | A-24P20            | 21 x 17 (53 x 43)        | 11.0 (5.0)     |
| A-242408LP      | 24 x 24 x 8 (61 x 61 x 20)  | 3.0 (7.6)  | 42.0 (19.1)    | A-24P24            | 21 x 21 (53 x 53)        | 13.0 (5.9)     |
| A-302408LP      | 30 x 24 x 8 (76 x 61 x 20)  | 3.0 (7.6)  | 57.0 (25.9)    | A-30P24            | 27 x 21 (69 x 53)        | 18.0 (8.2)     |
| A-362408LP      | 36 x 24 x 8 (91 x 61 x 20)  | 3.0 (7.6)  | 68.0 (30.8)    | A-36P24            | 33 x 21 (83 x 53)        | 23.0 (10.4)    |
| A-363008LP      | 36 x 30 x 8 (91 x 76 x 20)  | 3.0 (7.6)  | 82.0 (37.2)    | A-36P30            | 33 x 27 (83 x 69)        | 27.0 (12.2)    |
| A-422408LP      | 42 x 24 x 8 (107 x 61 x 20) | 3.0 (7.6)  | 103.0 (46.7)   | A-42P24            | 39 x 21 (99 x 53)        | 25.0 (11.3)    |
| A-423608LP      | 42 x 36 x 8 (107 x 91 x 20) | 3.0 (7.6)  | 113.0 (51.3)   | A-42P36            | 39 x 33 (99 x 83)        | 39.0 (17.7)    |
| A-483608LP      | 48 x 36 x 8 (122 x 91 x 20) | 3.0 (7.6)  | 122.0 (55.3)   | A-48P36            | 45 x 33 (114 x 83)       | 46.0 (20.9)    |
| A-603608LP      | 60 x 36 x 8 (152 x 76 x 20) | 3.0 (7.6)  | 148.0 (67.1)   | A-60P36            | 57 x 33 (145 x 83)       | 58.0 (26.3)    |

\* Order panels separately. Contact Kele for additional NEMA 12 sizes.

Please see the Accessories page for latch kits, lock kits, electric heaters, ventilation kits, and cooling fans.