



ENCLOSURES

HOFFMAN NEMA 1 ENCLOSURES AND PANELS

A SERIES LARGE

DESCRIPTION


Hoffman **A Series Large** NEMA 1 enclosures house controls and instruments in areas that do not require oil- and dust-tight ratings.

FEATURES

- **Continuous hinges**
- **Mounting holes on back of enclosure**
- **Easy operation of flush latch with a screwdriver or coin**
- **Collar studs provided for mounting optional panels**
- **ANSI 61 gray polyester-powder coated**
- **Door and body stiffeners for extra rigidity**
- **Optional steel panels with white finish**
- **Optional locks and latches available**
- **UL listed, File #E27567**
- **CSA certified, File #LL42186**
- **One-year warranty**



DIMENSIONS

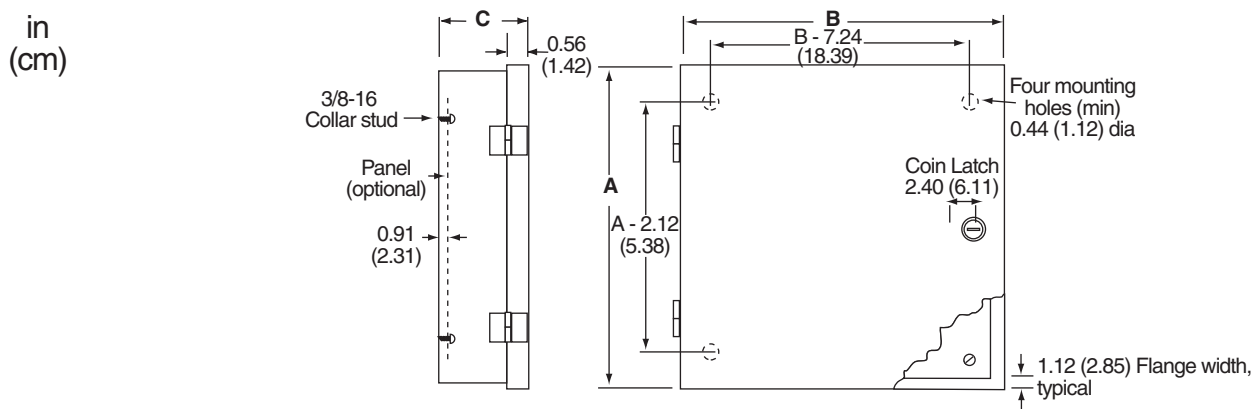

ORDERING INFORMATION

ENCLOSURE MODEL	DIMENSIONS A x B x C in (cm)	BODY GAUGE	WEIGHT lb (kg)	SOLID PANEL** MODEL	DIMENSIONS H x W in (cm)	GAUGE	WEIGHT lb (kg)
A-42N3009*	42 x 30 x 9.25 (107 x 76 x 24)	14	101 (45.9)	A-42P30*	39 x 27 (99 x 69)	12	33 (15.0)
A-42N3609*	42 x 36 x 9.25 (107 x 91 x 24)	14	122 (55.4)	A-42P36*	39 x 33 (99 x 84)	12	39 (17.7)
A-48N3609*	48 x 36 x 9.25 (122 x 91 x 24)	14	124 (56.3)	A-48P36*	45 x 33 (114 x 84)	12	46 (20.9)
A-42N3013*	42 x 30 x 13.25 (107 x 76 x 34)	14	112 (50.9)	A-42P30*	39 x 27 (99 x 69)	12	33 (15.0)
A-42N3613	42 x 36 x 13.25 (107 x 91 x 34)	14	132 (59.9)	A-42P36	39 x 33 (99 x 84)	12	39 (17.7)
A-48N3613	48 x 36 x 13.25 (122 x 91 x 34)	14	144 (65.4)	A-48P36	45 x 33 (114 x 84)	12	46 (20.9)

* Stocked at Kele. Other size enclosures and panels are special order and cannot be returned for credit. ** Order panels separately. See Accessories page for locks, latches, louvers, fans, and heaters.