

ENCLOSURES

HOFFMAN NEMA 1 ENCLOSURES AND PANELS

A SERIES MEDIUM



DESCRIPTION

Hoffman **A Series Medium** NEMA 1 enclosures house controls and instruments in areas that do not require oil-tight and dust-tight ratings.

FEATURES

- Removable doors with butt hinges
- Mounting holes on back of enclosure
- Easy operation of flush latch with a screwdriver or coin
- Collar studs provided for mounting optional panels
- ANSI 61 gray polyester-powder coating inside and out over phosphatized surfaces
- Optional steel panels with white finish
- UL listed, File #E27567
- CSA certified, File #LL42184
- One-year warranty




6

ENCLOSURES

DIMENSIONS

in
(cm)

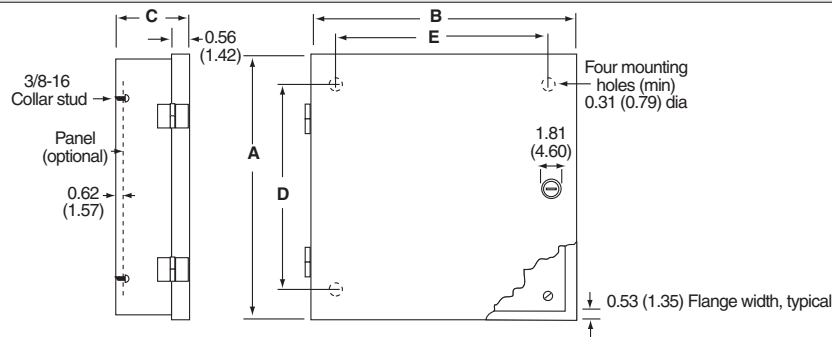

ORDERING INFORMATION

ENCLOSURE MODEL†	DIMENSIONS		BODY GAUGE	WEIGHT lb (kg)	SOLID PANEL* MODEL	SIZE H x W in (cm)	GAUGE	WEIGHT lb (kg)
	A x B x C in (cm)	MOUNTING D x E in (cm)						
A-16N12ALP	16 x 12 x 6.62 (41 x 31 x 17)	13.88 x 7 (35 x 18)	16	15.0 (6.8)	A-16N12MP	13 x 10.5 (33 x 27)	14	3.0 (1.4)
A-16N16ALP	16 x 16 x 6.62 (41 x 41 x 17)	13.88 x 11 (35 x 28)	16	22.5 (10.2)	A-16N16MP	13 x 14.5 (33 x 37)	14	5.0 (2.3)
A-16N20ALP	16 x 20 x 6.62 (41 x 51 x 17)	13.88 x 15 (35 x 38)	16	21.5 (9.8)	A-16N20MP	13 x 18.5 (33 x 47)	14	6.0 (2.7)
A-20N16ALP	20 x 16 x 6.62 (51 x 41 x 17)	17.88 x 11 (45 x 28)	16	21.5 (9.8)	A-20N16MP	17 x 14.5 (43 x 37)	14	6.0 (2.7)
A-20N20ALP	20 x 20 x 6.62 (51 x 51 x 17)	17.88 x 15 (45 x 38)	16	26.0 (11.8)	A-20N20MP	17 x 18.5 (43 x 47)	14	7.0 (3.2)
A-24N16ALP	24 x 16 x 6.62 (61 x 41 x 17)	21.88 x 11 (56 x 28)	16	26.0 (11.8)	A-24N16MP	21 x 14.5 (53 x 37)	14	7.0 (3.2)
A-24N20ALP	24 x 20 x 6.62 (61 x 51 x 17)	21.88 x 15 (56 x 38)	16	30.0 (13.6)	A-24N20MP	21 x 18.5 (53 x 47)	14	9.0 (4.1)
A-24N24ALP	24 x 24 x 6.62 (61 x 61 x 17)	21.88 x 19 (56 x 48)	14	40.0 (18.1)	A-24N24MP	21 x 22.5 (53 x 57)	12	15.0 (6.8)
A-30N24ALP	30 x 24 x 6.62 (76 x 61 x 17)	27.5 x 16.75 (70 x 43)	14	49.5 (22.5)	A-30N24MP	26 x 22.5 (66 x 57)	12	18.5 (8.4)
A-36N24ALP	36 x 24 x 6.62 (91 x 61 x 17)	33.5 x 16.75 (85 x 43)	14	52.2 (23.7)	A-36N24MP	32 x 22.5 (81 x 57)	12	23.0 (10.4)
A-36N30ALP	36 x 30 x 6.62 (91 x 76 x 17)	33.5 x 22.75 (85 x 58)	14	69.0 (31.3)	A-36N30MP	32 x 28.5 (81 x 72)	12	29.0 (13.2)
A-16N12BLP	16 x 12 x 8.62 (41 x 31 x 22)	13.88 x 7 (35 x 18)	16	17.0 (7.7)	A-16N12MP	13 x 10.5 (33 x 27)	14	6.0 (2.7)
A-20N16BLP	20 x 16 x 8.62 (51 x 41 x 22)	17.88 x 11 (45 x 28)	16	25.5 (11.6)	A-20N16MP	17 x 14.5 (43 x 37)	14	6.0 (2.7)
A-20N20BLP	20 x 20 x 8.62 (51 x 51 x 22)	17.88 x 15 (45 x 38)	16	30.5 (13.8)	A-20N20MP	17 x 18.5 (43 x 47)	14	7.0 (3.2)
A-24N20BLP	24 x 20 x 8.62 (61 x 51 x 22)	21.88 x 15 (56 x 38)	16	33.0 (15.0)	A-24N20MP	21 x 18.5 (53 x 47)	14	9.0 (4.1)
A-24N24BLP	24 x 24 x 8.62 (61 x 61 x 22)	21.88 x 19 (56 x 48)	14	42.0 (19.1)	A-24N24MP	21 x 22.5 (53 x 57)	12	15.0 (6.8)
A-30N24BLP	30 x 24 x 8.62 (76 x 61 x 22)	27.5 x 16.75 (70 x 43)	14	50.5 (22.9)	A-30N24MP	26 x 22.5 (66 x 57)	12	18.5 (8.4)
A-30N30BLP	30 x 30 x 8.62 (76 x 76 x 22)	27.5 x 22.75 (70 x 58)	14	61.5 (27.9)	A-30N30MP	26 x 28.5 (66 x 72)	12	23.5 (10.7)
A-36N24BLP	36 x 24 x 8.62 (91 x 61 x 22)	33.5 x 16.75 (85 x 43)	14	54.2 (24.6)	A-36N24MP	32 x 22.5 (81 x 57)	12	23.0 (10.4)
A-36N30BLP	36 x 30 x 8.62 (91 x 76 x 22)	33.5 x 22.75 (85 x 58)	14	68.0 (30.8)	A-36N30MP	32 x 28.5 (81 x 72)	12	29.0 (13.2)
A-24N20CLP	24 x 20 x 10.62 (61 x 51 x 27)	21.88 x 15 (56 x 38)	16	36.0 (16.3)	A-24N20MP	21 x 18.5 (81 x 47)	14	9.0 (4.1)
A-24N24DLP	24 x 24 x 12.62 (61 x 61 x 27)	21.88 x 19 (56 x 48)	14	51.0 (23.1)	A-24N24MP	21 x 22.5 (53 x 57)	12	15.0 (6.8)
A-30N24DLP	30 x 24 x 12.62 (76 x 61 x 27)	27.5 x 16.75 (70 x 43)	14	62.5 (28.4)	A-30N24MP	26 x 22.5 (66 x 57)	12	18.5 (8.4)
A-36N30DLP	36 x 30 x 12.62 (91 x 76 x 27)	33.5 x 22.75 (85 x 58)	14	81.0 (36.7)	A-36N30MP	32 x 28.5 (81 x 72)	12	29.0 (13.2)

* Order panels separately

† Add P to the end of the part number to order optional perf panel.

See Accessories page for locks, latches, louvers, fans and heaters.

RELATED PRODUCT

Perf panel