



ENCLOSURES

HOFFMAN NEMA 4 ENCLOSURES AND PANELS

A-ALP, A-BLP SERIES

DESCRIPTION

Hoffman A-ALP and A-BLP Series NEMA 4 enclosures are designed to house electrical and pneumatic controls, instruments, and components. These enclosures provide protection from windblown dust and rain, splashing water, and hose-directed water.



A-ALP, A-BLP Series


Hoffman®



FEATURES

- Continuously welded or ground-smooth seam, no holes or knockouts
- Seamless, watertight foam gasket for tight seal
- Hasp and staple for padlocking
- Removable door
- Data pocket included
- Collar studs provided for mounting optional subpanels
- Steel subpanels available
- Fans, heaters, louvers, and windows available
- UL File #E61997
- CSA File #LR42186, RoHs
- One-year warranty

DIMENSIONS

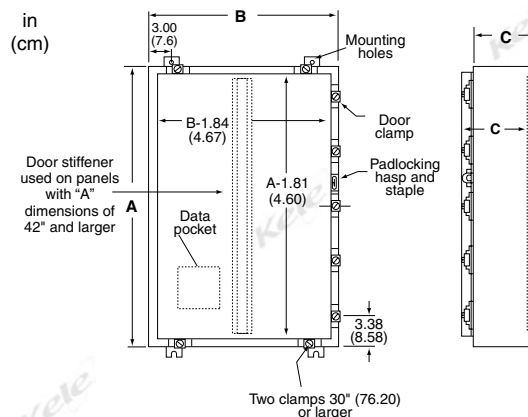

ORDERING INFORMATION

ENCLOSURE*				SOLID STEEL SUBPANEL**			
MODEL	DIMENSIONS A x B x C in (cm)	BODY GAUGE	WEIGHT lb (Kg)	MODEL	DIMENSIONS A x B in (cm)	GAUGE	WEIGHT lb (Kg)
A-16H12ALP	16 x 12 x 6 (41 x 30 x 15)	16	17.9 (8.1)	A-16P12	13 x 9 (33 x 23)	12	3.7 (1.7)
A-16H16ALP	16 x 16 x 6 (41 x 41 x 15)	16	24.4 (11.1)	A-16P16	13 x 13 (33 x 33)	12	5.2 (2.4)
A-20H16ALP	20 x 16 x 6 (51 x 41 x 15)	16	25.5 (11.6)	A-20P16	17 x 13 (43 x 33)	12	6.9 (3.1)
A-20H20ALP	20 x 20 x 6 (51 x 51 x 15)	16	29.7 (13.5)	A-20P20	17 x 17 (43 x 43)	12	8.9 (4.0)
A-24H20ALP	24 x 20 x 6 (61 x 51 x 15)	16	34.1 (15.5)	A-24P20	21 x 17 (53 x 43)	12	11 (5.0)
A-24H24ALP	24 x 24 x 6 (61 x 61 x 15)	16	39 (17.7)	A-24P24	21 x 21 (53 x 53)	12	14 (6.4)
A-30H24ALP	30 x 24 x 6 (76 x 61 x 15)	14	54 (24.5)	A-30P24	27 x 21 (69 x 53)	12	18.7 (8.5)
A-36H24ALP	36 x 24 x 6 (91 x 61 x 15)	14	61 (27.7)	A-36P24	33 x 21 (83 x 53)	12	22.0 (10.0)
A-16H12BLP	16 x 12 x 8 (41 x 30 x 20)	16	19.8 (9.0)	A-16P12	13 x 9 (33 x 23)	12	3.7 (1.7)
A-20H16BLP	20 x 16 x 8 (51 x 41 x 20)	16	27.8 (12.6)	A-20P16	17 x 13 (43 x 33)	12	6.9 (3.2)
A-20H20BLP	20 x 20 x 8 (51 x 51 x 20)	16	32.5 (14.7)	A-20P20	17 x 17 (43 x 43)	12	8.9 (4.0)
A-24H20BLP	24 x 20 x 8 (61 x 51 x 20)	16	40.7 (18.5)	A-24P20	21 x 17 (53 x 43)	12	11 (5.0)
A-24H24BLP	24 x 24 x 8 (61 x 61 x 28)	16	43 (19.5)	A-24P24	21 x 21 (53 x 53)	12	14 (6.4)
A-30H24BLP	30 x 24 x 8 (76 x 61 x 20)	14	58 (26.3)	A-30P24	27 x 21 (69 x 53)	12	18.7 (8.5)
A-36H24BLP	36 x 24 x 8 (91 x 61 x 20)	14	67.0 (30.4)	A-36P24	33 x 21 (83 x 53)	12	22.0 (10.0)
A-36H30BLP	36 x 30 x 8 (91 x 76 x 20)	14	80 (36.3)	A-36P30	33 x 27 (83 x 69)	12	29.6 (13.4)

Call Kele for sizes other than those listed.

* Add a -P after enclosure number to include a solid steel subpanel. Add -PF after enclosure number to include a Perf Panel.

** Order panels separately.