

PANEL FABRICATION

GENERAL-PURPOSE SELECTOR SWITCHES

ASW SERIES



DESCRIPTION

ASW Series General-purpose Selector Switches are for pilot duty control of electrical equipment such as fans, pumps, compressors, or control circuits.

FEATURES

- *Rugged, oil-tight construction*
- *Snap-fit blocks with N.O. and N.C. contacts*
- *Self-cleaning silver contacts*
- *Durable nylon operator base*
- *Optional key or lever styles available*

SPECIFICATIONS

Contact rating	10A, 600 VAC/VDC 5 mA, 3 VAC/VDC minimum
Contact resistance	50 mΩ maximum (initial value)
Rated insulation voltage	600V
Mechanical life	500,000 minimum operations
Electrical life	500,000 minimum operations
Terminals	#6-40 (M3.5) screws
Contact material	Silver
Mounting	0.878" (2.23 cm) hole
Panel thickness	Panel thickness adjustment ring, 0.04" to 0.24" (0.10 to 0.61 cm)
Protection rating	NEMA 1, 2, 3, 3R, 4, 4X, 12, 13
Agency approvals	UL listed, File #E70646; CSA certified, File #LR48366
Warranty	1 year



SSG1-67



ASW320
mounted in
E-1PBG




ACSNO-354-YB-
C3016



Knob Style Selector Switch



DIMENSIONS

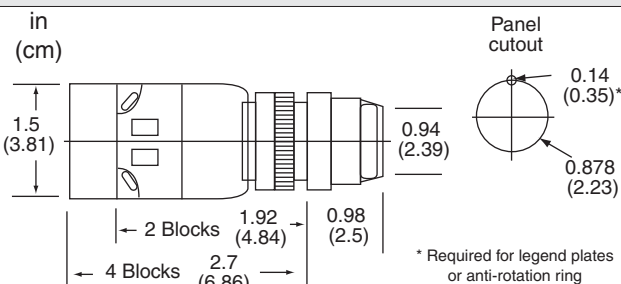

Knob Style

ORDERING INFORMATION

SELECTOR SWITCHES												
TWO-POSITION MAINTAINED					THREE-POSITION MAINTAINED					ADDITIONAL CONTACT BLOCKS		
Model	Contact Configuration	Contact #	Operator Position		Model	Contact Configuration	Contact #	Operator Position			HW-C10 Normally open contact HW-C01 Normally close contact TW-DB Dummy block (needed when only one HW-C10 or HW-C01 is used)	
			L	R				L	C	R		
ASW210 ASW2K10 (Key)	1 N.O.	1	O	X	ASW320 ASW3K20 (Key)	2 N.O.	1 2	X O	O O	O X		
ASW201-116	1 N.C.	1	X	O	ASW321-255	2 N.O. 1 N.C.	1 2 3	X O O	O X O	O X X		
ASW211 ASW2K11 (Key)	1 N.O. 1 N.C.	1 2	X O	O X	ASW322 ASW3K22 (Key)	2 N.O. 2 N.C.	1 2 3 4	X O O X	O O -X -X	O X - O		
NWAL-212	Legend Plate-Off-On				NWAL-317	Legend Plate-Hand-Off-Auto						Note: Key is removeable in any position
X = Contacts closed O = Contacts open -X-X = Contacts remain closed when switch is moved between these two positions.												
CAM SWITCHES												
ACSNO-244-YB-C2008		Four-position, contact made each position only, 45 degrees (1.2", 3.05 cm mounting hole)										
ACSNO-354-YB-C3016		Five-position, contact made each position only, 45 degrees (1.2", 3.05 cm mounting hole)										

Call Kele for selector switches with key or lever operators, other contact arrangements, and other legend plates.

RELATED PRODUCTS
 E-1PBG One-hole NEMA 12/13 push-button enclosure
 E-2PBG* Two-hole NEMA 12/13 push-button enclosure
 E-3PBG* Three-hole NEMA 12/13 push-button enclosure
 E-4PBG* Four-hole NEMA 12/13 push-button enclosure
 SSG1-67 Wall plate box mount 7/8" hole
 NWAL-Custom Custom engraved nameplate

* Holes are 22.5 mm in a vertical arrangement.