

THERMOSTATS & CONTROLLERS

THERMOSTAT GUARDS TG500, ATK, TG SERIES



DESCRIPTION

The **TG, AT and BAPI-Guard Thermostat Guards** are used to enclose and protect wall thermostats and sensors against tampering, damage, and unauthorized adjustment of thermostat settings.

FEATURES

TG500 Series Vented Guards

- Patented, double-wall construction
- Available in various sizes
- Clear plastic, or painted steel
- Includes ring base, cover, lock, and two keys

BAPI-Guard Series Vented Guards

- Clear low-profile design
- All mounting hardware included
- Key lock for vertical or horizontal mounting
- Two sizes to fit most applications
- Hammer tough

ATK Series

- Available in wire and cast aluminum
- Vertical and horizontal mounting

TG Series Vented Guards


- One-piece, UV-stabilized, high-impact molded polycarbonate housing
- Ring base is 16-gauge steel with white finish and four mounting holes
- Stainless steel fasteners secure housing to base
- Ventilation holes allow air to circulate freely



BAPI-GUARD



TG510A

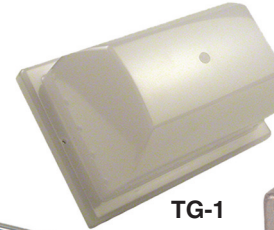

TG-1



ATK03



ATK04

ORDERING INFORMATION

MODEL	SIZE	COVER	RING BASE	SOLID WALL PLATE	INSIDE DIMENSIONS			OUTSIDE DIMENSIONS		
					Height	Width	Depth	Height	Width	Depth
					in (cm)	in (cm)	in (cm)	in (cm)	in (cm)	in (cm)
TG509F1003	Small	Smoke	Clear	—	4.0 (10.2)	2.8 (7.1)	1.8 (4.6)	5.5 (14.0)	3.6 (9.1)	2.1 (5.3)
TG510A1001		Clear	Clear	Opaque	4.38 (11.13)	4.38 (11.13)	2.25 (5.72)	5.88 (14.94)	5.88 (14.94)	2.5 (6.35)
TG510D1005		Painted Steel (off-white)	Opaque	Opaque						
BA/BG2		Clear	Clear	—	4.8 (12.3)	2.9 (7.4)	1.43 (3.65)	6.75 (17)	4.75 (12)	2.1 (5.4)
ATK03		Wire	—	—	4.25 (10.80)	2.63 (6.66)	1.63 (4.12)	—	—	—
ATK04		Cast Aluminum	—	—	4.25 (10.80)	2.75 (6.98)	1.63 (4.12)	—	—	—
TG511A1000	Medium	Clear	Clear	Opaque	5.06 (12.85)	6.06 (15.39)	2.63 (6.68)	6.5 (16.51)	7.5 (19.05)	2.94 (7.47)
TG511D1004		Painted Steel (off-white)	Opaque	Opaque						
TG-1	Large	Pearlescent	White	—	2.8 (7.1)	5.0 (12.7)	3.1 (7.9)	5.375 (13.7)	7.75 (19.7)	4.25 (10.8)
TG-2		Clear	White	—	2.8 (7.1)	5.0 (12.7)	3.1 (7.9)	5.375 (13.7)	7.75 (19.7)	4.25 (10.8)
TG-37		Prismatic	White	—	3.0 (7.6)	5.5 (14.0)	3.1 (7.9)	5.875 (14.9)	8.5 (21.6)	4.125 (10.5)
TG512A1009		Clear	Clear	Opaque	5.88 (14.94)	8.38 (21.29)	3.0 (7.62)	7.25 (18.42)	9.75 (24.77)	3.38 (8.59)
TG512D1003		Painted Steel (off-white)	Opaque	Opaque						
BA/BG		Clear	Clear	—	6.9 (17.5)	4.7 (11.8)	1.75 (4.43)	9.45 (24)	6.7 (16.8)	3.0 (7.6)
ATK63		Wire	—	—	6.50 (16.51)	6.38 (16.21)	3.0 (7.62)	—	—	—