



ENCLOSURES

HOFFMAN NEMA 4, 12, AND 13 ENCLOSURES AND PANELS C-SD CONCEPT SERIES

DESCRIPTION

Hoffman **C-SD Concept Series** enclosures are attractive, single-door wall-mounted enclosures designed to safely house electrical and pneumatic components. Manufactured from 14- or 16-gauge steel, depending on size, seams are continuously welded and ground smooth, so there are no holes or knock-outs. These enclosures provide protection from dust, dirt, oil, and water. **Concept Series** enclosures are rated NEMA 4, 12, and 13.

FEATURES

- *Minimum width body flange for maximum door opening*
- *Hidden hinges for clean aesthetic appearance*
- *Door removable by pulling captive hinge pins*
- *Seamless foam-in-place one-piece gasket for oil-tight and dust-tight seal*
- *Furnished with all hardware for wall mounting and seals for the mounting holes*
- *Panel-mounting studs for optional subpanel and accessories*
- *Door bar on hinge side for wire management and ground*
- *Provisions on door for thermoplastic data pocket*
- *UL listed, File #E61977; CSA certified, File #LR42186*
- *Rated NEMA 4, 12, and 13*
- *ANSI 61 gray polyester powder coating inside and out with white panels*
- *Six enclosure sizes available in RAL 9001 beige polyester powder coating*




C-SD16126



C-SD16126-BG



DIMENSIONS

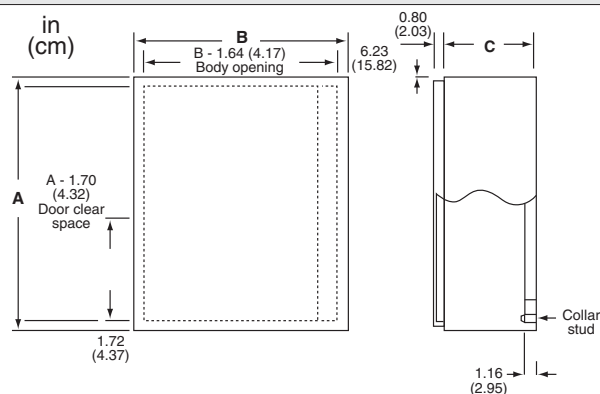

ORDERING INFORMATION

ENCLOSURE					SOLID STEEL PANEL*			
MODEL GRAY	MODEL BEIGE	DIMENSIONS A x B x C in (cm)	BODY GAUGE	WEIGHT lb (kg)	MODEL	DIMENSIONS A x B in (cm)	GAUGE	WEIGHT lb (kg)
C-SD12126	C-SD12126-BG	12 x 12 x 6 (30 x 30 x 15)	16	12.0 (5.4)	C-P1212	10.2 x 10.2 (26 x 26)	12	2.4 (1.1)
C-SD16126	C-SD16126-BG	16 x 12 x 6 (41 x 30 x 15)	16	16.0 (7.3)	C-P1612	14.5 x 10.2 (37 x 26)	12	3.4 (1.5)
C-SD20166	C-SD20166-BG	20 x 16 x 6 (51 x 41 x 15)	16	22.0 (10.0)	C-P2016	18.2 x 14.5 (46 x 37)	12	7.9 (3.6)
C-SD20206		20 x 20 x 6 (51 x 51 x 15)	16	26.0 (11.8)	C-P2020	18.2 x 18.2 (46 x 46)	12	10.0 (4.5)
C-SD24206	C-SD24206-BG	24 x 20 x 6 (61 x 20 x 15)	16	30.0 (13.6)	C-P2420	22.2 x 18.2 (56 x 46)	12	13.0 (5.9)
C-SD24246		24 x 24 x 6 (61 x 61 x 15)	16	36.9 (16.7)	C-P2424	22.2 x 22.2 (56 x 56)	12	13.0 (5.9)
C-SD16128		16 x 12 x 8 (41 x 30 x 20)	16	16.0 (7.3)	C-P1612	14.2 x 10.2 (36 x 26)	12	3.4 (1.5)
C-SD20168		20 x 16 x 8 (51 x 30 x 20)	16	24.3 (11.0)	C-P2016	18.2 x 14.2 (46 x 36)	12	7.9 (3.6)
C-SD24208		24 x 20 x 8 (61 x 51 x 20)	16	32.3 (14.7)	C-P2420	22.2 x 18.2 (56 x 46)	12	13.0 (5.9)
C-SD24248		24 x 24 x 8 (61 x 61 x 20)	16	39.7 (18.0)	C-P2424	22.2 x 22.2 (56 x 56)	12	13.0 (5.9)
C-SD30248	C-SD30248-BG	30 x 24 x 8 (76 x 61 x 20)	16	46.0 (20.9)	C-P3024	28.2 x 22.2 (72 x 56)	12	18.0 (8.2)
C-SD36248		36 x 24 x 8 (91 x 61 x 20)	16	55.0 (24.9)	C-P3624	34.2 x 22.2 (87 x 56)	12	23.6 (10.7)
C-SD36308	C-SD36308-BG	36 x 30 x 8 (91 x 76 x 20)	14	77.0 (34.9)	C-P3630	34.2 x 28.2 (87 x 72)	12	30.4 (13.8)
C-SD363010		36 x 30 x 10 (91 x 76 x 25)	14	99.0 (44.9)	C-P3630	34.2 x 28.2 (87 x 72)	12	30.4 (13.8)
C-SD423610		42 x 36 x 10 (107 x 91 x 25)	14	114.4 (51.9)	C-P4236	40.2 x 34.2 (102 x 87)	12	43.0 (19.5)
C-SD483610		48 x 36 x 10 (122 x 91 x 25)	14	126.0 (57.2)	C-P4836	46.2 x 34.2 (117 x 87)	12	50.0 (22.7)
C-SD603610		60 x 36 x 10 (152 x 91 x 25)	14	151.0 (68.5)	C-P6036	58.2 x 34.2 (148 x 87)	12	58.0 (26.3)

Call Kele for sizes other than those listed.
See the Accessories page for heaters and fans.

* Order panels separately.
+ Add P to the end of model number to include solid steel subpanel.

RELATED PRODUCTS

CWHK

Keylock handle for Concept Series