



ENCLOSURES

NEMA 1 HINGE COVER BOXES

HC SERIES

DESCRIPTION

The **Kele HC Series** NEMA 1 hinge cover boxes serve as surface-mounted junction boxes or switch boxes. With the addition of a field-installed perforated subpanel, they can also house controls and instruments in areas that do not require oil-tight and dust-tight ratings.

FEATURES


- 16-gauge steel construction meets NEMA 1
- Removable doors with butt hinges
- Door hinge on left or right side
- Mounting holes on back of enclosure
- Easy operation of flush latch with a screwdriver or coin
- Various sizes of easily removable knockouts on all sides
- ANSI 61 gray polyester-powder finish inside and out over phosphatized surfaces
- Available with optional perf panel
- UL File #E27525
- CSA File #LL42184, RoHS
- One-year warranty



HC Series



DIMENSIONS

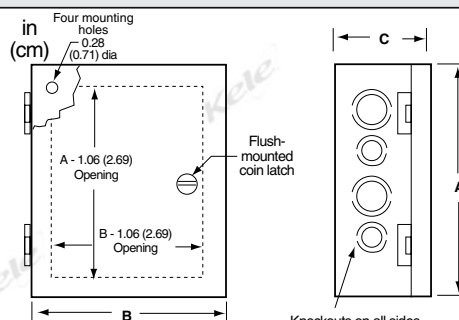

ORDERING INFORMATION

ENCLOSURE MODEL†	DIMENSIONS A x B x C in (cm)	WEIGHT lb (Kg)	OPTIONAL PERF PANEL DIMENSION SIZE H x W in (cm)
HC664	6 x 6 x 4 (15 x 15 x 10)	3.2 (1.5)	4.25 x 4.25 (11 x 11)
HC666	6 x 6 x 6 (15 x 15 x 15)	4.0 (1.8)	4.25 x 4.25 (11 x 11)
HC886	8 x 8 x 6 (20 x 20 x 15)	6.0 (2.7)	6.25 x 6.25 (16 x 16)
HC1084	10 x 8 x 4 (25 x 20 x 10)	7.0 (3.2)	8.25 x 6.25 (21 x 16)
HC1284	12 x 8 x 4 (30 x 20 x 10)	8.0 (3.6)	10.25 x 6.25 (26 x 16)
HC12104	12 x 10 x 4 (30 x 25 x 10)	8.0 (3.6)	10.25 x 8.25 (26 x 21)
HC12124	12 x 12 x 4 (30 x 30 x 10)	8.8 (4.0)	10.25 x 10.25 (26 x 26)
HC12126	12 x 12 x 6 (30 x 30 x 15)	10.3 (4.7)	10.25 x 10.25 (26 x 26)
HC16124	16 x 12 x 4 (41 x 30 x 10)	12.0 (5.5)	14.25 x 10.625 (36 x 26)
HC16126	16 x 12 x 6 (41 x 30 x 15)	13.0 (5.9)	14.25 x 10.25 (36 x 26)
HC18124	18 x 12 x 4 (46 x 30 x 10)	12.0 (5.4)	16.25 x 10.25 (41 x 26)
HC18126	18 x 12 x 6 (46 x 30 x 15)	14.0 (6.4)	16.25 x 10.25 (41 x 26)

† Add **P** to the end of part number to order optional perf panel. (Standoffs are field installed, drilling required.)

See Hoffman Enclosure Accessory page in the Enclosure section for locks, latches, heaters, fans, and ventilation kits. Additional box sizes available.