


Product data sheet

Specifications

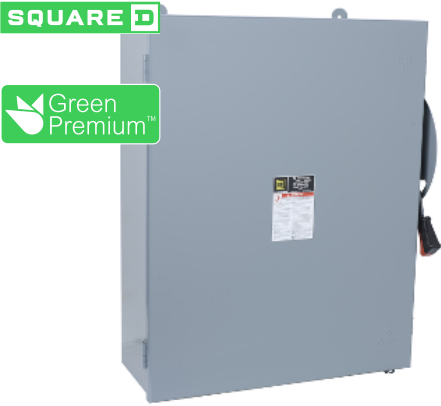

Safety switch, heavy duty, non fusible, 200A, 4 poles, 150hp, 600VAC/DC, NEMA 12

HU464AWK

Product availability : Stock - Normally stocked in distribution facility

Price* : 2,832.00 USD

Main

Product	Single Throw Safety Switch
Duty Rating	Heavy duty
Device Application	Heavy application
Disconnect Type	Non-fusible disconnect
Factory Installed Neutral	None
Phase	3 phase
Number of Poles	4
Current Rating	200 A
Voltage Rating	600 V AC/DC
Enclosure Rating	NEMA 3R/12 galvanized steel
Maximum Horse Power Rating	50 hp 240 V at AC 50-60 Hz for 2 phases conforming to NEC 430.52 60 hp 240 V at AC 50-60 Hz for 3 phase conforming to NEC 430.52 50 hp 480 V at AC 50-60 Hz for 2 phases conforming to NEC 430.52 125 hp 480 V at AC 50-60 Hz for 3 phase conforming to NEC 430.52 50 hp 600 V at AC 50-60 Hz for 2 phases conforming to NEC 430.52 150 hp 600 V at AC 50-60 Hz for 3 phase conforming to NEC 430.52 40 hp 250 V at DC 50 hp 600 V at DC

Complementary

Mounting Type	Surface
Electrical Connection	Lugs
Wiring configuration	4-wire
Wire Size	AWG 6...250 kcmil copper or aluminium
Tightening torque	275 lbf.in (31.07 N.m) 0.02...0.20 in² (13.3...127 mm²) (AWG 6...250 kcmil)
Depth	8.75 in (222.25 mm)
Width	18.63 in (473.20 mm)
Height	29 in (736.60 mm)
Net Weight	80.49 lb(US) (36.51 kg)

Environment

Certifications	UL listed file E2875
----------------	----------------------

* Price is “List Price” and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Ordering and shipping details

Category	00116-H&HU SW,4&6P,N12,30-200A
Discount Schedule	DE1
GTIN	785901505976
Returnability	Yes
Country of origin	US

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	25.00 in (63.5 cm)
Package 1 Width	7.13 in (18.11 cm)
Package 1 Length	16.50 in (41.91 cm)
Package 1 Weight	54.95 lb(US) (24.925 kg)


Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	Product Environmental Profile
PVC free	Yes

Contractual warranty



Warranty	18 months
----------	-----------

Dimensions

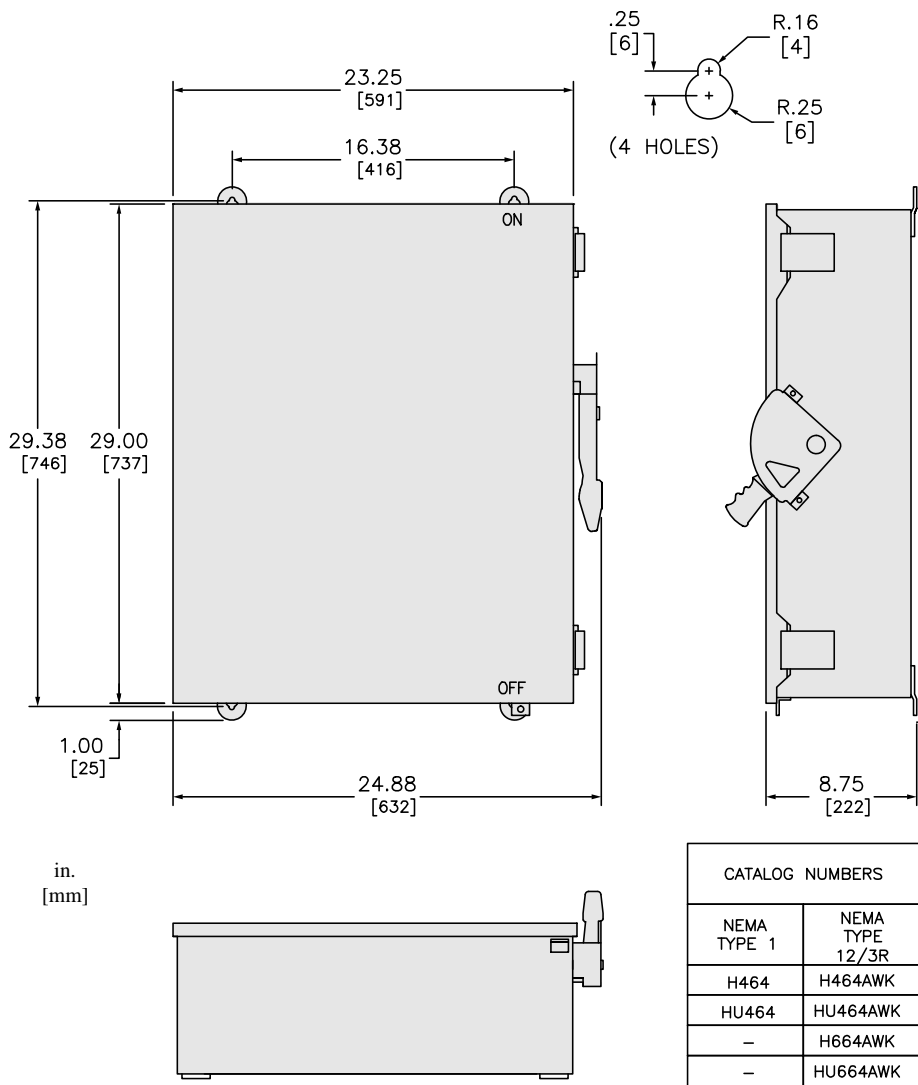

ALL DIMENSIONS ARE APPROXIMATE.
REFER TO TECHNICAL DRAWINGS AND DOCUMENTATION FOR COMPLETE INFORMATION.
WHEN MOUNTING THESE SWITCHES, ALLOW 3.75/[95] MIN CLEARANCE BETWEEN ENCLOSURES
FOR OPENING OF SIDE HINGED DOOR.

Wiring Diagram

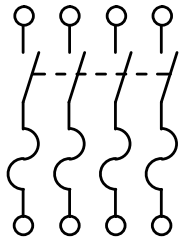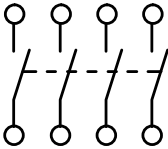WIRING DIAGRAMS	
FUSIBLE	NOT FUSIBLE
	
H464 H464AWK	HU464 HU464AWK

Recommended replacement(s)