



FlexPower - Unified Power Solutions™

System power, lock power, controllers


- One enclosure, one ac drop
- Up to 35% installation savings, 50% space savings
- Managed models for remote service and predictive diagnostics

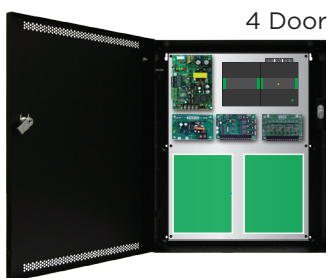

4 Door

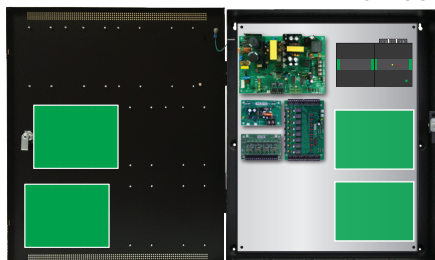

8 Door

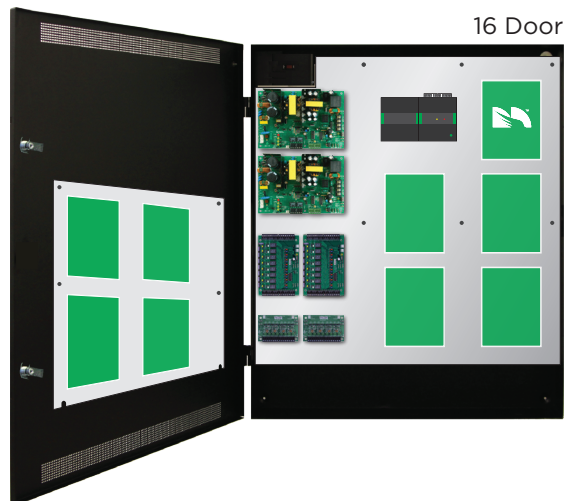

16 Door

Dual Voltage examples

Standard - single and dual voltage

Doors	Voltage	Model Number	Power	Outputs	ENCLOSURE H x W x D
4 Door	Single	AXV-75-4DRE2M	6A/12V (3A/24V)	8 Auxiliary	20 X 16 X 4.5
8 Door	Single	AXV-150-8DRE4M1	12A/12V (6A/24V)	8 Auxiliary	24 X 20 X 4.5
16 Door	Single	AXV-150-16DRE4M1	12A/12V (6A/24V)	16 Auxiliary	24 X 20 X 4.5
16 Door	Single	AXV-150-16DRE6M1	12A/12V (6A/24V)	16 Auxiliary	30 X 23 X 6.5
16 Door	Single	AXV-150-16DRE8M1	12A/12V (6A/24V)	16 Auxiliary	36 X 30 X 4.5
4 Door	Dual	AXV-75D-4DRE2M	2A/12V and 2A/24V	8 Auxiliary / 4 Control	20 X 16 X 4.5
8 Door	Dual	AXV-150D-8DRE4M1	4A/12V and 4A/24V	8 Auxiliary / 8 Control	24 X 20 X 4.5
16 Door	Dual	AXV-400D-16DRE6M1	12A/12V and 10A/24V	16 Auxiliary / 16 Control	30 X 23 X 6.5
16 Door	Dual	AXV-400D-16DRE8M1	12A/12V and 10A/24V	16 Auxiliary / 16 Control	36 X 30 X 4.5

Networked - single and dual voltage

Doors	Voltage	Model Number	Power	Outputs	ENCLOSURE H x W x D
4 Door	Single - NetLink	AXV-75-4DRE2MN	6A/12V (3A/24V)	8 Auxiliary	20 X 16 X 4.5
8 Door	Single - NetLink	AXV-150-8DRE4M1N	12A/12V (6A/24V)	8 Auxiliary	24 X 20 X 4.5
16 Door	Single - NetLink	AXV-150-16DRE6M1N	12A/12V (6A/24V)	16 Auxiliary	30 X 23 X 6.5
16 Door	Single - NetLink	AXV-150-16DRE8M1N	12A/12V (6A/24V)	16 Auxiliary	36 X 30 X 4.5
4 Door	Dual - ISCAN	AXV-75D-4DRE4MN	2A/12V and 2A/24V	8 Auxiliary / 8 Managed	24 X 20 X 4.5
8 Door	Dual - ISCAN	AXV-150D-8DRE4M1N	4A/12V and 4A/24V	8 Auxiliary / 8 Managed	24 X 20 X 4.5
16 Door	Dual - ISCAN	AXV-400D-16DRE6M1N	12A/12V and 10A/24V	16 Auxiliary / 16 Managed	30 X 23 X 6.5
16 Door	Dual - ISCAN	AXV-400D-16DRE8M1N	12A/12V and 10A/24V	16 Auxiliary / 16 Managed	36 X 30 X 4.5

"NetLink" monitors power supplies & battery set

"ISCAN" monitors power supplies, battery sets and 8 -16 connected devices



Save on Service

Traditional service functions performed remotely

- Power cycle frozen devices (cameras, locks, panels)
- System battery load testing

Monitor / Control / Report


Total System Health - faults, output draw, battery state, temperatures

Output Condition - current draw, voltage level and output status

Battery Activity - charging current, discharge level, time to service

Power History - AC outages, site fault log

»» Unified Power Features

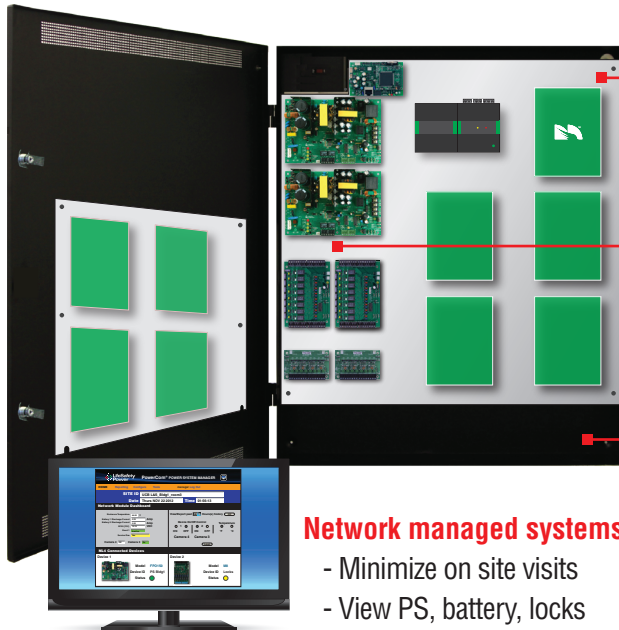

Network managed systems

- Minimize on site visits
- View PS, battery, locks
- NetLink: PS & battery monitoring
- ISCAN: PS, batteries and 8 - 16 outputs

Custom back plates for access and power

- Enclosure options support two to sixteen doors single or dual voltage with remote management
- Pre-installed SSC din rail


Pre-wired power section saves installation time

- 120 or 230VAC input with safe AC disconnect

Installation and service efficiencies

- One AC drop reduces installation costs
- Removable back plate simplifies access wiring
- Removable knockouts on all four sides
- 4.5" enclosure depth accommodates large battery set

»» Enclosure Sizes

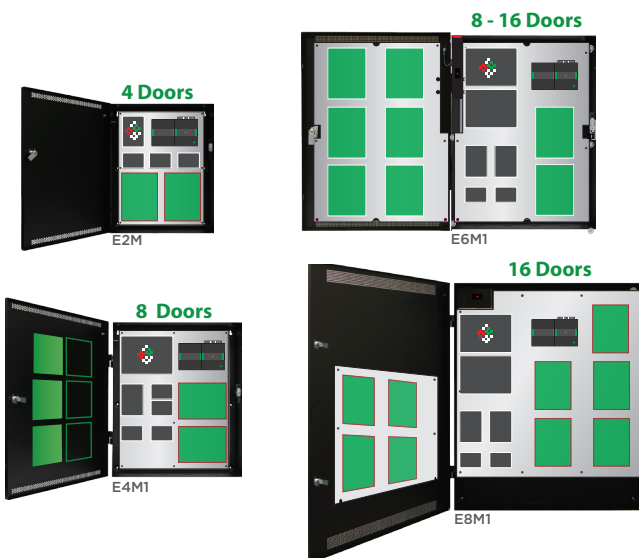

Door Mounting

- 4** E2M 20 x 16 x 4.5"
- 8** E4M1 24 x 20 x 4.5"
- 8+** E6M1 30 x 23 x 6.5"
- 16** E8M1 36 x 30 x 4.5"

Lockset & tamper switch included



Schneider branded