



PNEUMATICS & FITTINGS

MISCELLANEOUS PIPE FITTINGS

M SERIES, F-1000 SERIES

90° DROP EAR ELBOW


Model	Description	Std. Pack
M-127	1/8" FPT	25



Drop Ear Elbow

GLOBE VALVES

Model	Cross Reference				Description (in)	Std. Pack
	Robertshaw	Johnson	Siemens	Honeywell		
M-132	20-973	F-1000-98	-	2030	1/2 FPT	10

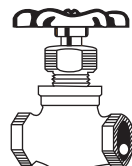

Globe Valve

SHUT OFF COCKS

Model	Cross Reference				Description (in)	Std. Pack
	Robertshaw	Johnson	Siemens	Honeywell		
M-135	-	F-1000-218	-	-	1/8 FPT	10
M-136	-	F-1000-219	-	2108	1/4 FPT	10



Shut Off

HEX NIPPLES

Model	Cross Reference				Description (in)	Std. Pack
	Robertshaw	Johnson	Siemens	Honeywell		
M-141	20-990	-	-	1739T	1/8 MPT	25
M-142	20-992	-	-	1751T	1/4 MPT	50
M-143	-	-	-	1762T	3/8 MPT	25




Hex Nipples

GANG STRAPS AND CLIPS

Model	Description	Std. Pack
M-633	Copper-plated six-gang strap	100
M-648-K	Capillary mounting clip 1/8" maximum	1
CC-1G	Non-metallic capillary clip 3/8" maximum	1


PIPE CLAMPS - Copper Plated

Model	Description (in)	Std. Pack
M-622	1/4 single	100
M-623	3/8 single	100
M-628	1/4-1/4 dual	100

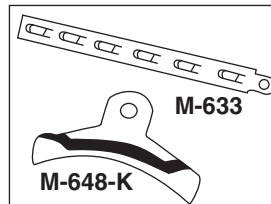

M-633

M-648-K

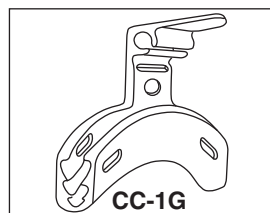

CC-1G



Snap-In Bushing

Model	Description	Std. Pack
F-1000-331	Nylon bushing, 1/2" EMT thru-wall conduit	50
F-1000-332	Nylon bushing, 3/4" EMT thru-wall conduit	50
NB12K	Nylon bushing, 1/2" knockout (7/8" hole)	50
CCT1820	Nylon bushing, 1/2" EMT and 1/2" knockout	50
2157	Nylon bushing, 3/4" knockout	1

ORDERING INFORMATION

Sold in package quantities only
Order quantity 1 = 1 package