

# Product data sheet

Specifications

SQUARE D



MP Meter Pak, meter center, six ringless sockets, no bypass, 5th jaw, OH, UG, 800 A bus, 200 A, 240 VAC single phase 3W

MPR86200

Product availability : Stock - Normally stocked in distribution facility

Price\* : 4,241.00 USD

### Main

|                         |              |
|-------------------------|--------------|
| Product                 | Meter Center |
| Socket Rating           | 200 A        |
| Main Type               | Main Lugs    |
| Number of Jaws          | 5            |
| Number of Meter Sockets | 6            |
| Socket Type             | Ringless     |

### Complementary

|                        |                                                                 |
|------------------------|-----------------------------------------------------------------|
| Main Rating            | 600 A<br>750 A                                                  |
| Bus Rating             | 800 A                                                           |
| Certifications         | UL Listed                                                       |
| Type                   | Meter-Pak                                                       |
| Busbar Material        | Aluminium busbar                                                |
| Bypass Type            | No bypass                                                       |
| Enclosure Material     | Steel                                                           |
| Enclosure Rating       | NEMA 3R                                                         |
| Maximum Voltage Rating | 120/240 V AC                                                    |
| Mounting               | Surface                                                         |
| Phase                  | 1 phase                                                         |
| Service Feed Location  | UG<br>OH                                                        |
| Wire Size              | AWG 3/0...500 kcmil 2 aluminium<br>AWG 3/0...500 kcmil 2 copper |
| Wire Configuration     | 3-wire                                                          |
| Height                 | 43.41 in (1102.61 mm)                                           |
| Width                  | 46.68 in (1185.67 mm)                                           |
| Depth                  | 8.28 in (210.31 mm)                                             |

\* Price is “List Price” and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Ordering and shipping details

|                   |                 |
|-------------------|-----------------|
| Category          | 00021-METER-PAK |
| Discount Schedule | DE4             |
| GTIN              | 785901410492    |
| Returnability     | Yes             |
| Country of origin | MX              |

Packing Units

|                              |                          |
|------------------------------|--------------------------|
| Unit Type of Package 1       | PCE                      |
| Number of Units in Package 1 | 1                        |
| Package 1 Height             | 9.49 in (24.1 cm)        |
| Package 1 Width              | 44.69 in (113.5 cm)      |
| Package 1 Length             | 47.01 in (119.4 cm)      |
| Package 1 Weight             | 167.00 lb(US) (75.75 kg) |

Offer Sustainability

|                            |                                                                                                                                                                                                                                                                                             |
|----------------------------|---------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| California proposition 65  | WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a> |
| REACH Regulation           | <a href="#">REACH Declaration</a>                                                                                                                                                                                                                                                           |
| REACH free of SVHC         | Yes                                                                                                                                                                                                                                                                                         |
| EU RoHS Directive          | Compliant<br><a href="#">EU RoHS Declaration</a>                                                                                                                                                                                                                                            |
| Toxic heavy metal free     | Yes                                                                                                                                                                                                                                                                                         |
| Mercury free               | Yes                                                                                                                                                                                                                                                                                         |
| RoHS exemption information | <a href="#">Yes</a>                                                                                                                                                                                                                                                                         |
| China RoHS Regulation      | <a href="#">China RoHS declaration</a>                                                                                                                                                                                                                                                      |

Contractual warranty


|          |           |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|

# Product data sheet

## Technical Illustration

# MPR86200

## Dimensions

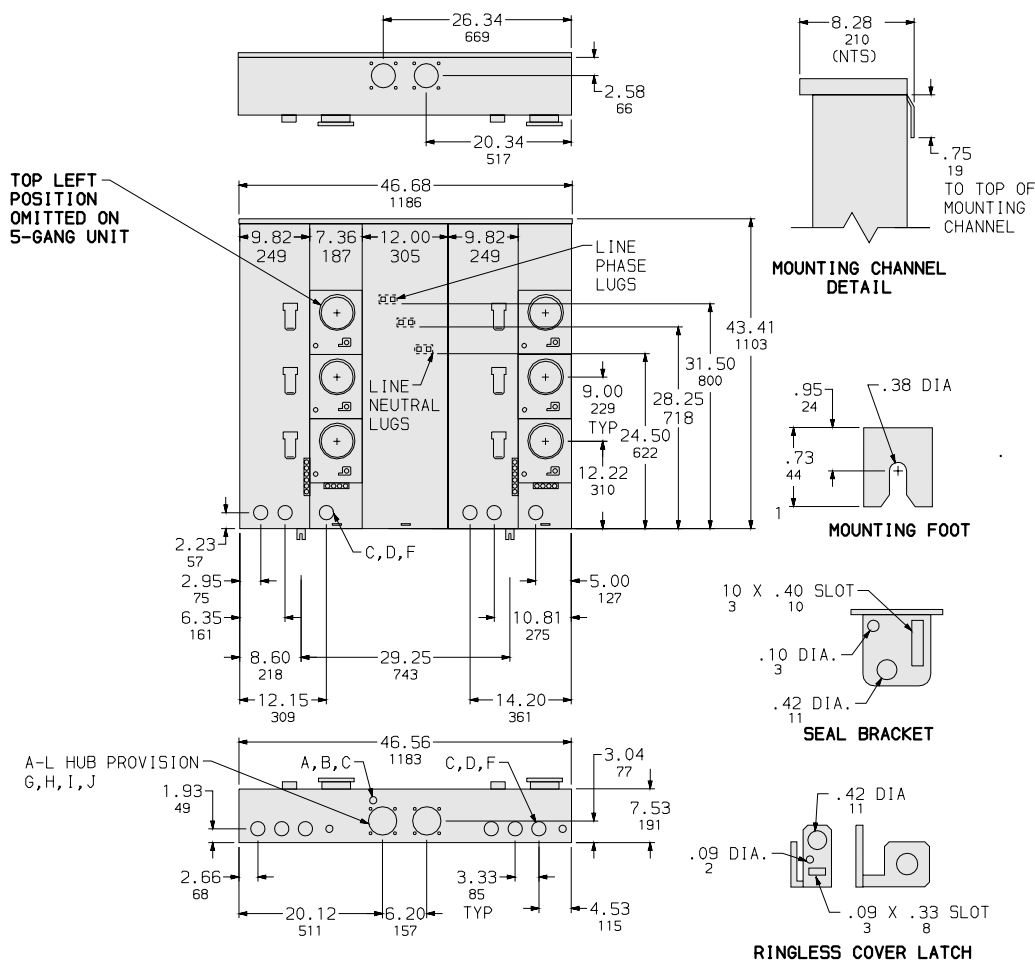


| KNOCKOUTS |              |     |               |     |
|-----------|--------------|-----|---------------|-----|
| SYMBOL    | CONDUIT SIZE |     | HOLE DIAMETER |     |
|           | IN           | MM  | IN            | MM  |
| A         | .50          | 13  | .88           | 22  |
| B         | .75          | 19  | 1.25          | 32  |
| C         | 1.00         | 25  | 1.38          | 35  |
| D         | 1.25         | 32  | 1.75          | 44  |
| E         | 1.50         | 38  | 2.00          | 51  |
| F         | 2.00         | 51  | 2.50          | 64  |
| G         | 2.50         | 64  | 3.00          | 76  |
| H         | 3.00         | 76  | 3.63          | 92  |
| I         | 3.50         | 89  | 4.13          | 105 |
| J         | 4.00         | 102 | 4.63          | 118 |

in.  
[mm]

ALL DIMENSIONS ARE APPROXIMATE.  
REFER TO CAD, TECHNICAL DRAWINGS,  
AND DOCUMENTATION FOR COMPLETE INFORMATION.

Wiring Diagram

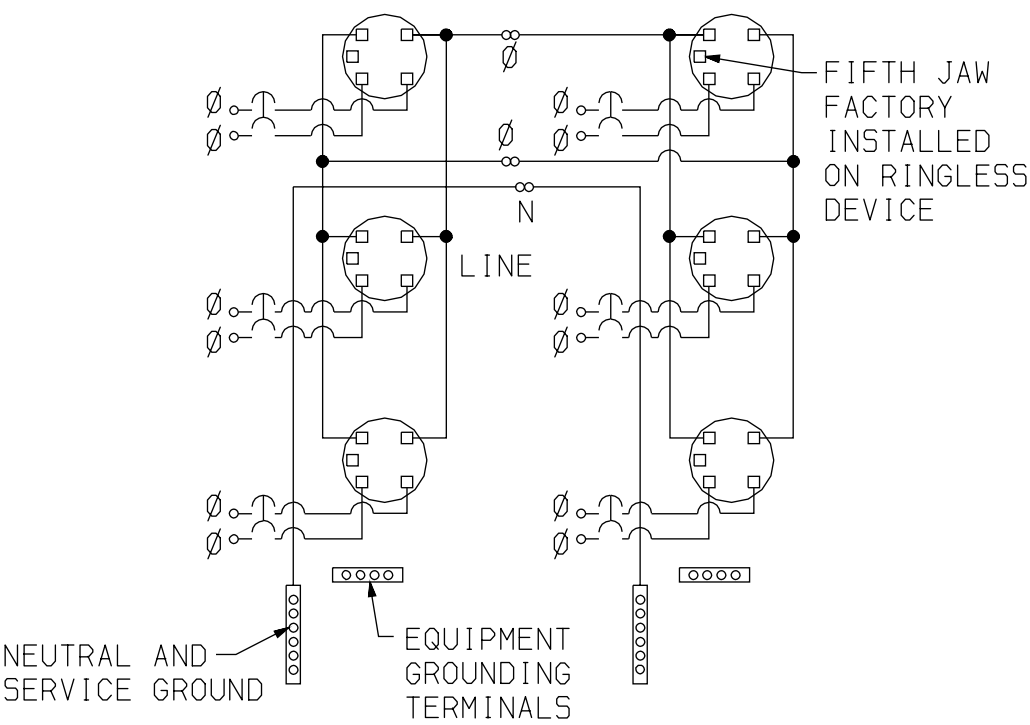

Recommended replacement(s)