


Product data sheet

Specifications

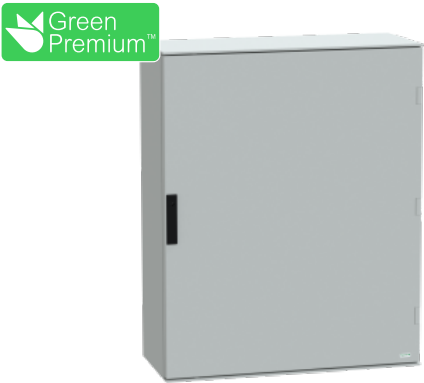

wall-mounting enclosure
polyester monobloc IP66
H1056xW852xD350mm

NSYPLM108G

Main

Range	Thalassa
Product name	Thalassa PLM
Device short name	PLM
Enclosure type	Multi-purpose
Category	Compact enclosure
Nominal height	1056 mm
Nominal width	852 mm
Nominal depth	350 mm
Enclosure mounting	Wall mounted
Device composition	1 body 1 door 1 lock
Door type	Plain
Lock type	4 points lock, handle with 5 mm double bar insert

Complementary

Number of locks	1
Mounting plate description	Without mounting plate
Accessibility for operation	Front
Removable parts	Door by hinges
Material	Polyester reinforced with fibreglass
Colour	Grey (RAL 7035)
Standards	NEMA classification 13 IEC 62208 NEMA classification 4X
Product certifications	UL
Electrical insulation class	Class II

Environment

IP degree of protection	IP66 conforming to IEC 60529
IK degree of protection	IK10 conforming to IEC 62262

Fire resistance	960 °C conforming to IEC 62208
Ambient air temperature for operation	-40...80 °C

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Weight	34.311 kg
Package 1 Height	38.5 cm
Package 1 width	86.5 cm
Package 1 Length	113.5 cm

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information
Environmental Disclosure	Product Environmental Profile