



WIRING AIDS AND DIN RAIL

P, DN SERIES, DIN RAIL

DESCRIPTION

The **P Series Spiralite** universal spiral wrapping is great for fast and economical grouping of wire bundles.

FEATURES

- **Polyethylene construction**
- **Provides flexible connection between panel and door**
- **Strong, yet simple to install and remove**

ORDERING INFORMATION

MODEL	FOR WIRE BUNDLES in (cm)	FT (m) (per carton*)
P2	1/4 to 1 (0.64 to 2.54)	80 (24)
P3	3/8 to 2 (0.95 to 5.08)	80 (24)
P4	1/2 to 3 (1.27 to 7.62)	65 (20)

* Available in carton quantities only – order quantity 1 = 1 carton



P Series

DESCRIPTION


The **DN Series** dinosaur duct is a flexible wiring duct for easy addition or removal of wiring.

FEATURES

- **Adhesive back for applications where mounting holes cannot be drilled**
- **Accommodates cables in restricted spaces**
- **Easily cut to desired length using scissors or knife**

ORDERING INFORMATION

MODEL	NOMINAL SIZE H x W in (cm)	LENGTH in (cm)	PIECES (per carton)*
White			
DN-25AW	0.50 x 0.75 (1.27 x 1.91)	19.7 (49.5)	24
DN-35AW	1.00 x 1.38 (2.54 x 3.51)	19.7 (49.5)	24
DN-45AW	1.38 x 1.75 (3.51 x 4.45)	19.7 (49.5)	14
Gray			
DN-25AG	0.50 x 0.75 (1.27 x 1.91)	19.7 (49.5)	24
DN-35AG	1.00 x 1.38 (2.54 x 3.51)	19.7 (49.5)	24
DN-45AG	1.38 x 1.75 (3.51 x 4.45)	19.7 (49.5)	14

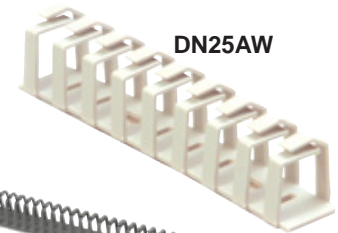

DN25AW



DN35-AG

DN Series
*Ordered per piece



DESCRIPTION

DIN rail is the standard method for mounting relays and terminal blocks. Kele offers four models with different features.


FEATURES

- **One meter length**
- **Perforated**
- **Steel or aluminum**

DIMENSIONS

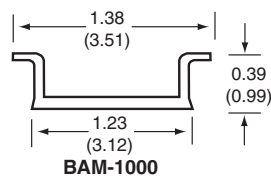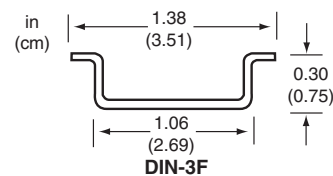

BAM-100
with DINCLIC-FM4
Mounting Clips

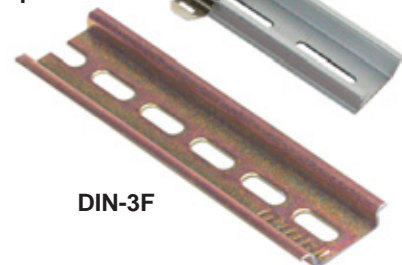

DIN-3F

ORDERING INFORMATION

MODEL	DESCRIPTION
BAM-1000	35 mm aluminum DIN mounting rail 39.4" (1m)
DIN-3F	35 mm DIN rail, steel, 39.4" (1m), RoHS compliant
DINRALU	DIN rail, aluminum
DINRSTL	DIN rail, steel

RELATED PRODUCTS

DINCLIC-FM4	Mounting clips, 4 mm screw size
--------------------	---------------------------------