



ENCLOSURES

NON-METALLIC BOXES

PS SERIES

DESCRIPTION

The versatile **Altech PS Series non-metallic boxes** are constructed only of flame-resistant materials. Rated for protection mode IP66 (similar to Nema 4X), these boxes give complete protection from dust, water jets, and even temporary flooding. Standard boxes from Kele have knockout side walls, gray bases, and gray covers. Optional fitting plates are available for easy mounting of control components inside the **PS Series**.

Altech Corp.®




PS1313-7



PS1313-7-T



DIMENSIONS

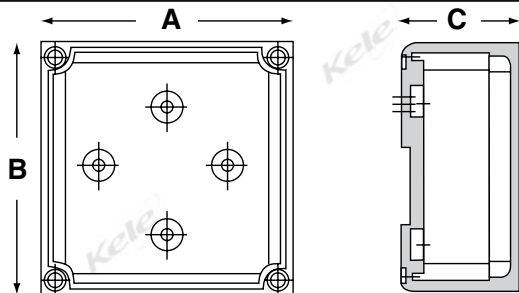

SPECIFICATIONS

Materials of Construction

Base/Cover/Plate Polystyrene, impact-resistant, non-flammable Seal Polyurethane

Color

Box & Cover

Light gray

-T Option

Smoke tinted

Flammability Rating

UL94 V2, 1760°F (960°C)

Temperature Rating

-40° to 158°F (-40° to 70°C)

Knockouts

1/2" NPT (2.3 cm),

3/4" NPT (2.9 cm)

ORDERING INFORMATION

BOX MODEL*	DIMENSIONS A x B x C in (cm)	PANEL PLATE MODEL	DIMENSIONS H x W in (cm)
PS1111-7	4.33 x 4.33 x 2.60 (11.0 x 11.0 x 6.6)	TK1111	3.54 x 3.54 (9.0 x 9.0)
PS1111-9	4.33 x 4.33 x 3.54 (11.0 x 11.0 x 9.0)	TK1111	3.54 x 3.54 (9.0 x 9.0)
PS1313-7	5.11 x 5.11 x 2.95 (13.0 x 13.0 x 7.5)	TK1313	4.33 x 4.33 (11.0 x 11.0)
PS1811-9	7.09 x 4.33 x 3.54 (18.0 x 11.0 x 9.0)	TK1811	5.91 x 3.54 (15.0 x 9.0)
PS1818-9	7.09 x 7.09 x 3.54 (18.0 x 18.0 x 9.0)	TK1818	5.91 x 5.91 (15.0 x 15.0)
PS2518-9	10.0 x 7.09 x 3.54 (25.4 x 18.0 x 9.0)	TK2518	8.66 x 5.91 (22.0 x 15.0)

* Add T to the end of model number for smoke-tinted transparent cover.
Fitting plates are plastic laminate 0.10" (0.25 cm) thick with screws furnished.
Call Kele for other box sizes and options.

PLASTIC ENCLOSURES

14121-000

DESCRIPTION


Model 14121-000 enclosures are constructed of impact-resistant polycarbonate and feature a transparent, gasketed cover that keeps out dust and water.



14121-000



DIMENSIONS

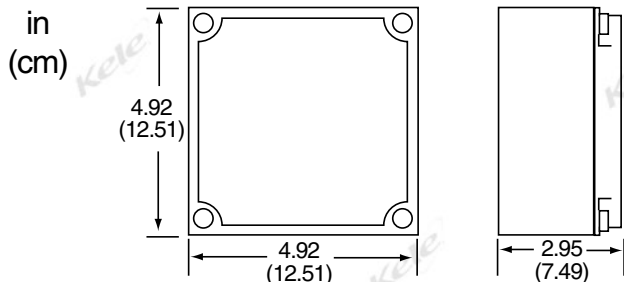

ORDERING INFORMATION

MODEL	DESCRIPTION
14121-000	Polycarbonate enclosure with transparent cover, 0.53 lb (0.24 kg)