

PANEL FABRICATION

WEIDMÜLLER DIN RAIL TERMINAL BLOCKS (STANDARD BEIGE) SAK4, SAK6




DESCRIPTION

Model SAK4 and **SAK6** DIN rail terminal blocks offer a modular design for flexibility in layout and reduced installation time. The standard color is beige for the terminal blocks and accessories, but other color terminal blocks are available. The **Model SAK4** offers maximum circuit density while the **Model SAK6** offers the convenience of larger screws for conventional screwdriver installation. Double-stacks and fuseholders are available. The markers are side mount in horizontal printing.

FEATURES

- **Wire secured by ribbed compression clamp**
- **Universal DIN rail mounting**
- **Reduced installation time**
- **Block removable without displacing adjacent blocks**




Weidmüller

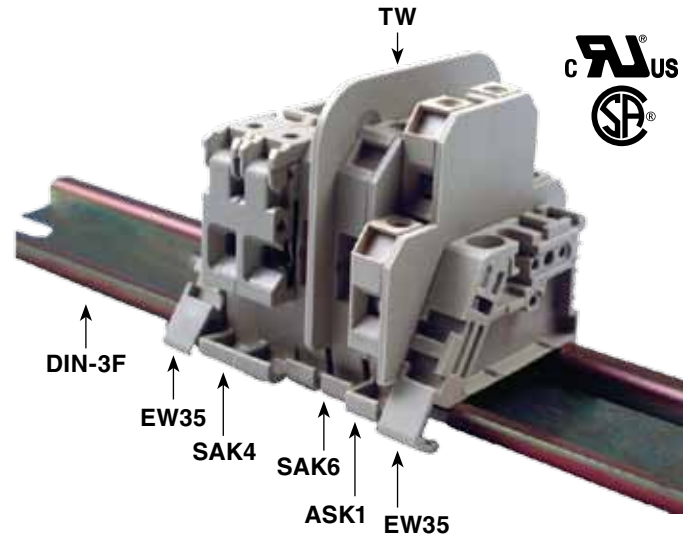

PANEL FABRICATION

15

DIMENSIONS

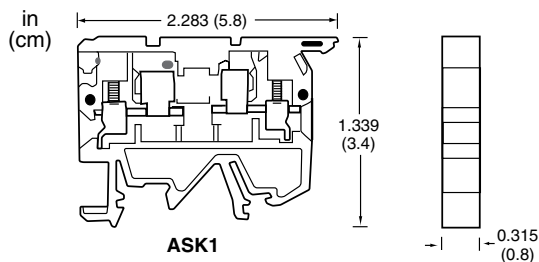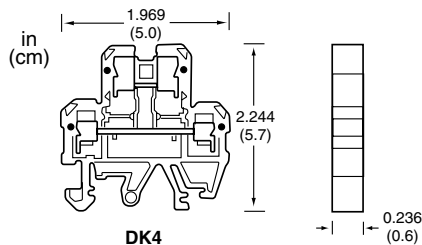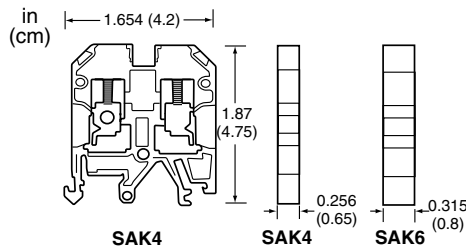

SPECIFICATIONS

Rated Voltage	600 VAC/VDC
Rated Current	30A UL, 36A CSA
Rated Wire Size	
SAK4	22-10 AWG
SAK6	22-8 AWG
Approvals	UL-recognized component, File #E60693; CSA certified

ORDERING INFORMATION

MODEL	DESCRIPTION	STDRD PKG*
SINGLE BEIGE 6 mm TERMINAL BLOCK		
SAK4	6 mm DIN rail terminal block, beige	100
EK4	6 mm grounding block, green and yellow	100
AP-SAK	End section, beige (one required)	100
EW35	End stop, beige (two required)	50
TW	Circuit separator, beige	20
FUSEHOLDERS		
ASK1	Fuseholder beige (K235 style fuse not included)	100
ASK1-LD	Fuseholder beige with 120 VAC/VDC indicator (K235 style fuse not included)	25
AP-ASK1	Fuseholder end section, beige (one required)	20
SINGLE BEIGE 8 mm TERMINAL BLOCK		
SAK6	8 mm DIN rail terminal block, beige	100
EK6	8 mm grounding block, green and yellow	100
AP-SAK	End section, beige (one required)	100
EW35	End stop, beige (two required)	50
TW	Circuit separator, beige	20
DOUBLE STACK BEIGE 6 mm TERMINAL BLOCK		
DK4	6 mm double stack terminal block, beige	100
AP-DK	End section, beige (one required)	20
EW35	End stop, beige (two required)	50
TW	Circuit separator, beige	20
SINGLE 6 mm TERMINAL BLOCK IN COLORS		
SAK4-BL	6 mm DIN rail terminal block, blue	100
SAK4-RD	6 mm DIN rail terminal block, red	100
SAK4-YW	6 mm DIN rail terminal block, yellow	100
SAK4-OR	6 mm DIN rail terminal block, orange	100
SAK4-GR	6 mm DIN rail terminal block, green	100
SAK4-GY	6 mm DIN rail terminal block, gray	100
SAK4-BK	6 mm DIN rail terminal block, black	100
SAK4-BR	6 mm DIN rail terminal block, brown	100
ACCESSORIES		
DINRSTL	35 mm steel DIN mounting rail, 39.4" (1m)	40
DINRALU	35 mm aluminum DIN mounting rail, 39.4" (1m)	40
Q10-6	6 mm 10 pole jumper bar with screws and spacers	20
Q10-8	8 mm 10 pole jumper bar with screws and spacers	20
DEKH-1/50	Horizontal numbers (one strip of 1-50)	10
DEKH-x/xx	Horizontal numbers (one strip of 50 numbers, fill in range, i.e. 51-100)	10
DEKH-LNG	Horizontal markers labeled L1, L2, L3, N, G	10
DEK-B	Blank markers	10
K235	Fuses	5

* May be ordered by piece