

## Product data sheet

### Characteristics


# 8502SBO1V02S

Non-Reversing Contactor, Size 0, 2-Pole, Open Style +Options

Product availability : Non-Stock - Not normally stocked in distribution facility



Price\*\* : 372.00 USD

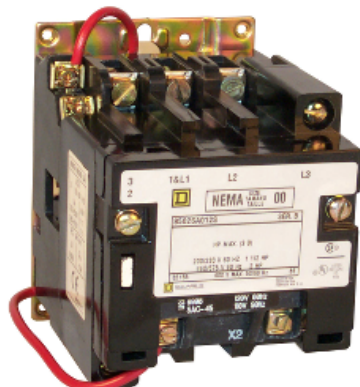

### Main

Product or component type	Contacteur
Type	8502S
Control Circuit Type	Separate control circuit
Control Circuit Voltage	110 V AC 50 Hz 120 V AC 60 Hz
Contacteur Type	Non-reversing
Line Rated Current	18 A
Number of Poles	2P
Phase	1 phase
Horsepower Rating	1 HP 115 V AC 2 HP 230 V AC
System Voltage	600 V AC
Control Units	No control units
Pilot Light	No indicator
Auxiliary Contacts	Without
Control Circuit Fusing	Fuse not supplied
Electrical connection	Screw clamp terminals
Enclosure Type	Not rated (open device)
Product certifications	CSA UL listed
NEMA size	0
Height	4.33 in (110 mm)
Depth	4.21 in (107 mm)
Width	3.23 in (82 mm)

### Ordering and shipping details

Category	21191 - 8502,36 SA,SB(NOT S*R,T,W)
----------	------------------------------------

Discount Schedule	CP1
GTIN	00785901761518
Nbr. of units in pkg.	1
Package weight(Lbs)	3.1800000000000002
Returnability	N
Country of origin	MX

### Offer Sustainability

RoHS (date code: YYWW)	Compliant - since 1545 - Schneider Electric declaration of conformity <a href="#">Schneider Electric declaration of conformity</a>
California proposition 65	WARNING: This product can expose you to chemicals including:
- - - - - Substance 1	Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm.
- - - - - More information	For more information go to <a href="http://www.p65warnings.ca.gov">www.p65warnings.ca.gov</a>

### Contractual warranty

Warranty period	18 months
-----------------	-----------