

Product data sheet

Characteristics


8502SCO2V03

NEMA Contactor, Type S, nonreversing, Size 1, 27A, 3 pole, 220/240 VAC 50/60 Hz coil, open style

Product availability : Stock - Normally stocked in distribution facility



Price** : 485.00 USD

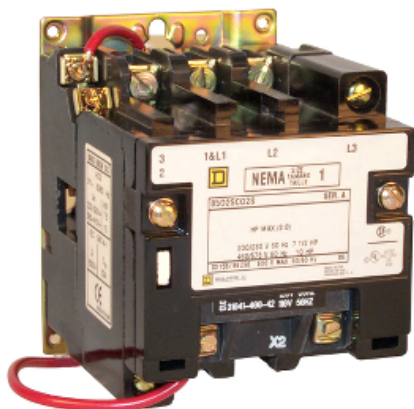

Main

Product or component type	Contacteur
Type	8502S
Control Circuit Type	Common control circuit
Control Circuit Voltage	240 V AC 60 Hz 220 V AC 50 Hz
Contacteur Type	Non-reversing
Current Rating	27 A
Number of Poles	3P
Phase	3 phase
Horsepower Rating	7.5 HP 200 V AC 7.5 HP 230 V AC 10 HP 460 V AC 10 HP 575 V AC
Maximum Voltage Rating	600 V AC
Control Units	No control units
Pilot Light	No indicator
Auxiliary Contacts	Without
Control Circuit Fusing	Fuse not supplied
Electrical connection	Screw clamp terminals
Enclosure Type	Not rated (open device)
Product certifications	UL Listed CSA
NEMA size	1
Maximum Height	4.33 in (110 mm)
Depth	4.21 in (107 mm)
Width	3.23 in (82 mm)

Ordering and shipping details

Category	21192 - 8502,36 SC,SD(NOT S*R,T,W)
Discount Schedule	CP1
GTIN	00785901764038
Nbr. of units in pkg.	1
Package weight(Lbs)	3.26 lb(US) (1.48 kg)
Returnability	Yes
Country of origin	MX

Packing Units

Package 1 Height	4.50 in (11.430 cm)
Package 1 width	5.90 in (14.986 cm)
Package 1 Length	8.00 in (20.320 cm)

Offer Sustainability

EU RoHS Directive	Not compliant
China RoHS Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information.

Contractual warranty

Warranty	18 months
----------	-----------