

Product data sheet

Characteristics


9050AO10DV02

Pneumatic Timing Relay, 15A, SPDT, off delay, 0.1 to 60 seconds, 110/120 VAC 50/60 Hz coil, open

Product availability : Non-Stock - Not normally stocked in distribution facility



Price** : 504.00 USD

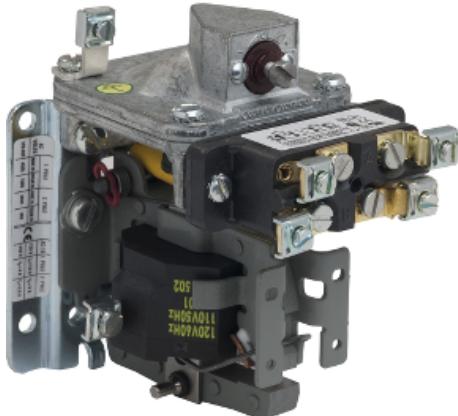

Main

| | |
|-------------------|----------------------------------|
| Product range | 9050A/H |
| Product type | Timer |
| Timing mode | Off-delay |
| Timing range | 0.1 s...1 min |
| Switch function | SPDT |
| Coil voltage | 120 V AC 60 Hz 110 V AC 50 Hz |
| Contact operation | Time delayed 1 NO + 1 NC |
| Current rating | 15 A |

Complementary

| | |
|---------------------------|---------------------------------------|
| Maximum switching voltage | 600 V AC |
| Electrical connection | Screw-clamp terminals |
| Reset response time | 29 ms - on-delay 27 ms - off-delay |
| Mounting support | Panel |

Environment

| | |
|---|--------------------------|
| Ambient temperature range - operational | 68...104 °F (20...40 °C) |
| Certifications | UL Listed CSA |
| Height | 2.64 in (67 mm) |
| Width | 4.02 in (102 mm) |
| Depth | 4.37 in (111 mm) |

Ordering and shipping details

| | |
|-------------------|---|
| Category | 21631 - 9050 A ONE MINUTE PNEUMATIC TIMER |
| Discount Schedule | CP1 |
| GTIN | 00785901864110 |
| Returnability | No |
| Country of origin | MX |

Offer Sustainability

| | |
|----------------------------|--|
| REACH free of SVHC | Yes |
| EU RoHS Directive | Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration |
| Mercury free | Yes |
| RoHS exemption information | Yes |
| China RoHS Regulation | China RoHS declaration Product out of China RoHS scope. Substance declaration for your information. |

Contractual warranty

| | |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|