


Product availability : Non-Stock - Not normally stocked in distribution facility

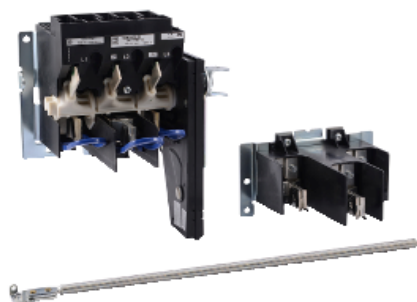

Price* : 918.50 USD



Main

Range	9422T
Product	Disconnect Switch
Disconnect Type	Fusible disconnect switch

Complementary

Mounting Type	Flange rod variable depth
Line Rated Current	100 A
Horsepower Rating	20 hp 250 V DC 25 hp 200 V AC 30 hp 230 V AC 60 hp 460 V AC 75 hp 575 V AC
Fuse Rating	100 A 250/600 V
Handle Type	Ordered separately
Fuse Type	H J R K

Environment


Certifications	CSA UL recognized
----------------	----------------------

Ordering and shipping details

Category	21732 - 9422
Discount Schedule	CP1
GTIN	00785901879831
Nbr. of units in pkg.	1
Package weight(Lbs)	6.969999999999998

Returnability	N
Country of origin	MX

Offer Sustainability

RoHS (date code: YYWW)	Compliant - since 1545 - Schneider Electric declaration of conformity  Schneider Electric declaration of conformity
California proposition 65	WARNING: This product can expose you to chemicals including:
- - - - - Substance 1	Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm.
- - - - - More information	For more information go to www.p65warnings.ca.gov

Contractual warranty

Warranty period	18 months
-----------------	-----------