

Product data sheet

Characteristics

HOM1224L125PGC

Load center, Homeline, 1 phase, 12 spaces,
24 circuits, 125A convertible main lugs, PoN,
NEMA1, grnd bar, combo cover

Product availability : Stock - Normally stocked in distribution facility



Price* : 204.00 USD



Main

Product or component type	Load Center
Marketing Trade Name	Homeline
Load center type	Main lugs
Line Rated Current	125 A
Number of spaces	12
Number of circuits	24
Enclosure Rating	NEMA 1 indoor
Cover type	Combination flush/surface cover
Electrical connection	Lugs
Included Options	Grounding bar 1)

Complementary

Short-circuit current	10 kA
Number of Tandem Breakers	6
Number of Phases	1 phase
[Ue] rated operational voltage	120/240 V AC
Wire Size	AWG 6...AWG 2/0 aluminium AWG 6...AWG 1 copper
Wiring configuration	3-wire
Cover finish	Gray baked enamel
Busbar Material	Tin plated aluminium busbar
Enclosure material	Welded sheet steel
Surface finish	Baked enamel Gray
Box number	4

* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Aug 17, 2020

Height	12.56 in (319 mm)
Width	8.90 in (226 mm)
Maximum Depth	4.25 in (108 mm)

Environment

Ambient air temperature for operation	23 °F (-5 °C) 104 °F (40 °C)
Product certifications	UL E-6294

Ordering and shipping details

Category	00045 - HOM LC&CVR,12-42 CKT,NEMA1
Discount Schedule	DE3C
GTIN	00785901864776
Nbr. of units in pkg.	1
Package weight(Lbs)	17.5 lb(US) (7.94 kg)
Returnability	Yes
Country of origin	US


Packing Units

Unit Type of Package 1	PCE
Package 1 Height	5.50 in (13.97 cm)
Package 1 width	16.30 in (41.402 cm)
Package 1 Length	21.00 in (53.34 cm)
Unit Type of Package 2	PAL
Number of Units in Package 2	42
Package 2 Weight	761.00 lb(US) (345.184 kg)
Package 2 Height	43.50 in (110.49 cm)
Package 2 width	40.00 in (101.6 cm)
Package 2 Length	48.00 in (121.92 cm)

Offer Sustainability

Sustainable offer status	Green Premium product
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration
Environmental Disclosure	Product Environmental Profile

Approximate Dimensions

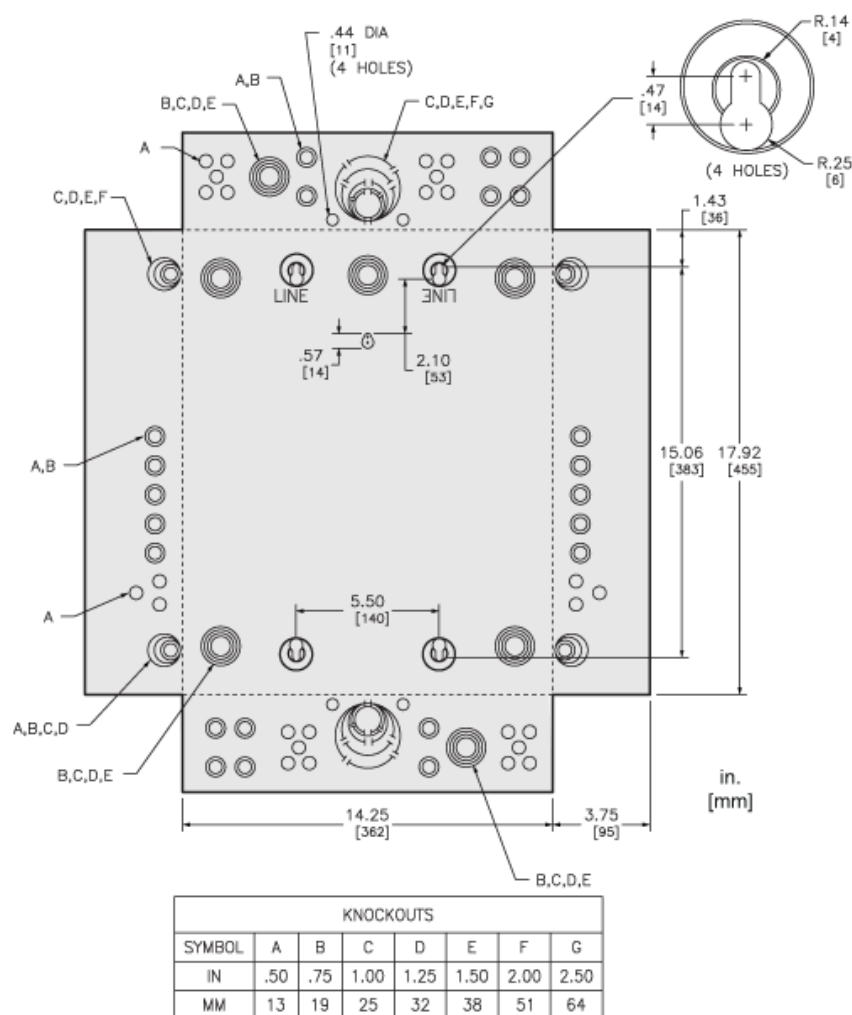

Connections and Wiring Diagrams

