

Product data sheet

Characteristics

HOM612L100RB

Load center, Homeline, 1 phase, 6 spaces, 12 circuits, 100A fixed main lugs, NEMA3R

Product availability : Stock - Normally stocked in distribution facility



Price** : 129.00 USD



Main

Product or component type	Load Center
Marketing Trade Name	Homeline
Load center type	Main lugs
Line Rated Current	100 A
Number of spaces	6
Number of circuits	12
Enclosure Rating	NEMA 3R outdoor
Cover type	Surface cover
Electrical connection	Lugs

Complementary

Short-circuit current	10 kA
Number of Tandem Breakers	6
Number of Phases	1 phase
[Ue] rated operational voltage	120/240 V AC
Wire Size	AWG 8...AWG 1 aluminium/copper
Wiring configuration	3-wire
Cover finish	Gray baked enamel
Busbar Material	Tin plated aluminium busbar
Enclosure material	Welded galvanized steel
Surface finish	Baked enamel Gray
Box number	2R
Height	12.64 in (321 mm)
Width	8.90 in (226 mm)
Depth	4.25 in (108 mm)

Environment

Ambient air temperature for operation	23 °F (-5 °C) 104 °F (40 °C)
Product certifications	UL E-6294

Ordering and shipping details

Category	00149 - HOM 2-8 CKT,MLO,NEMA1&3R
Discount Schedule	DE3C
GTIN	00785901061205
Returnability	Yes
Country of origin	MX


Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information.
Environmental Disclosure	Product Environmental Profile

Contractual warranty

Warranty	Lifetime
----------	----------

Approximate Dimensions

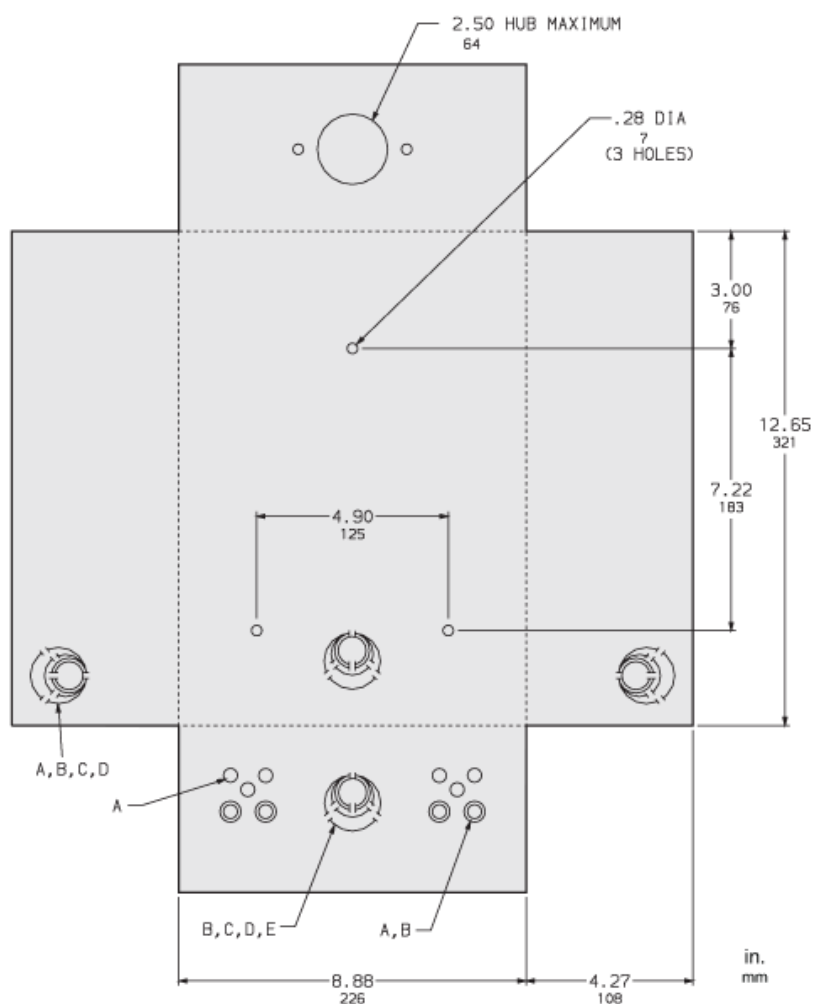

KNOCKOUTS					
SYMBOL	A	B	C	D	E
IN	.50	.75	1.00	1.25	1.50
MM	13	19	25	32	38

Connections and Wiring Diagrams

