

Product data sheet

Characteristics


QO124M150P

Load center, QO, 1 phase, 24 spaces, 24 circuits, 150A convertible main breaker, PoN, NEMA1, UL

Product availability : Stock - Normally stocked in distribution facility



Price* : 972.00 USD

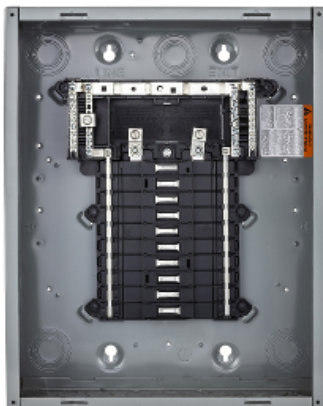

Main

Marketing Trade Name	QO
Product	Load Center

Complementary

Tightening torque	Cover 20 lb.in
Load Center Type	Main breaker
Line Rated Current	150 A
Number of spaces	24
Short Circuit Current Rating	22 kA
Maximum Number of Single Pole Circuits	24
Maximum Number of Tandem Breakers	12
Number of Phases	1 phase
Box number	9
Height	29.86 in (758.44 mm)
Maximum Width	14.25 in (361.95 mm)
Maximum Depth	3.75 in (95.25 mm)

Environment

Enclosure Rating	NEMA 1 indoor
Ambient air temperature for operation	23 °F (-5 °C) 104 °F (40 °C)
Product certifications	UL Listed


* Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Sep 23, 2020

Ordering and shipping details

Category	10001 - QO PON 1PH LC,12-60 CKT, MB N1
Discount Schedule	DE3A
GTIN	00785901609650
Nbr. of units in pkg.	1
Package weight(Lbs)	1 lb(US) (0.45 kg)
Returnability	Yes

Approximate Dimensions

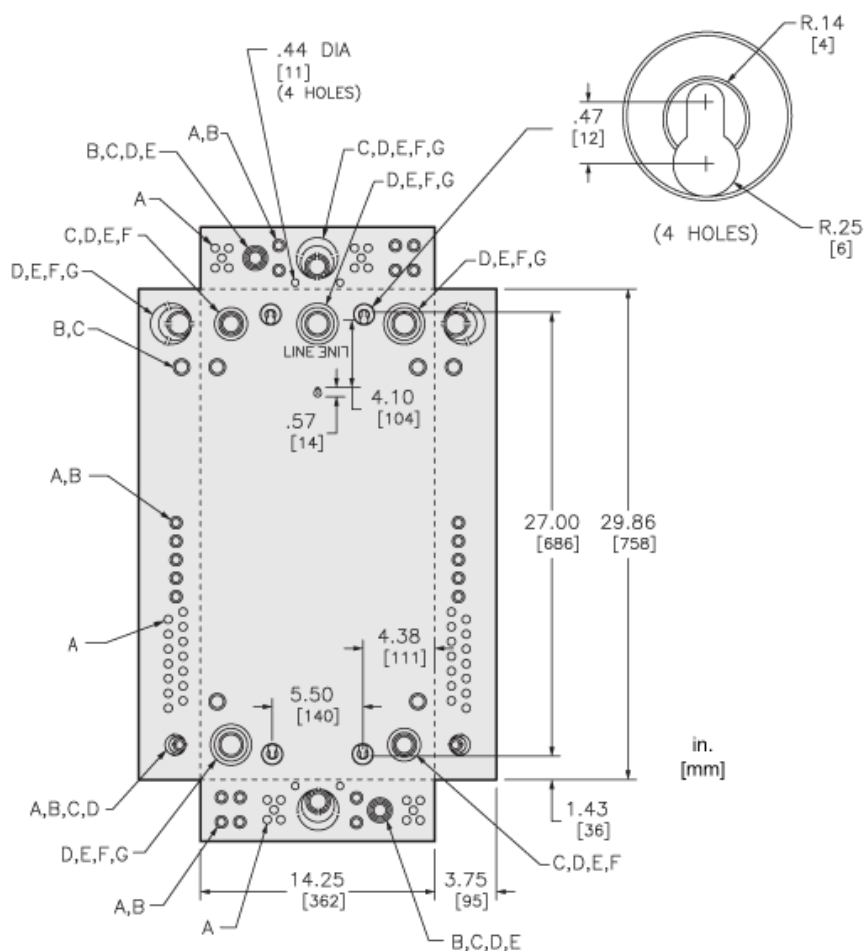

KNOCKOUTS							
SYMBOL	A	B	C	D	E	F	G
IN	.50	.75	1.00	1.25	1.50	2.00	2.50
MM	13	19	25	32	38	51	64

Connections and Wiring Diagrams

