

# Product data sheet

## Characteristics


### QO132M100PCVP

QO LoadCenter, PoN, main breaker, 100 A, 1 PH, 32 SP, NEMA1, cover, value pack

Product availability : Stock - Normally stocked in distribution facility



Price\*\* : 1,000.00 USD

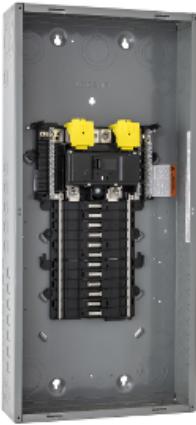

#### Main

Product	Load Center
Marketing Trade Name	QO
Provided equipment	Cover

#### Complementary

Load Center Type	Main breaker
Line Rated Current	100 A
Number of spaces	32
Short Circuit Current Rating	22 kA
Maximum Number of Single Pole Circuits	32
Maximum Number of Tandem Breakers	6
Number of Phases	1 phase
Box number	8
Height	661.42 mm (26.04 in)
Width	361.95 mm (14.25 in)
Depth	95.25 mm (3.75 in)

#### Environment

Enclosure Rating	NEMA 1
Ambient air temperature for operation	23 °F (-5 °C) 104 °F (40 °C)

#### Ordering and shipping details

Category	00184 - MISC. QO 1PH LOAD CENTERS
----------	-----------------------------------

Discount Schedule	DE3A
GTIN	00785901085904
Package weight(Lbs)	12.61 kg (27.81 lb(US))
Returnability	Yes
Country of origin	US