



Main

Range of product	Zelio Relay
Product or component type	Socket
Contact terminal arrangement	Mixed
Product compatibility	Plug-in relay RXM (4 C/O) Plug-in relay RXM (2 C/O)
Shape of pin	Flat
Device short name	RXZ
Sale per indivisible quantity	10

Complementary


[Ith] conventional free air thermal current	10 A
[Ue] rated operational voltage	< 250 V
Tightening torque	<= 1 N.m (M3 screw(s))
Fixing mode	Clip-on 35 mm symmetrical DIN rail By screw panel
Marking	CE
Width	27 mm
Product weight	0.056 kg

Environment

Connections - terminals	Connector, solid cable without cable end 2 x 0.5...2 x 1.5 mm²/AWG 20...AWG 16 Connector, solid cable without cable end 1 x 0.5...1 x 2.5 mm²/AWG 20...AWG 14 Connector, flexible cable with cable end 2 x 0.25...2 x 1 mm²/AWG 22...AWG 17 Connector, flexible cable with cable end 1 x 0.25...1 x 2.5 mm²/AWG 22...AWG 14
Standards	IEC 61984
Product certifications	CSA UL Lloyd's
Ambient air temperature for storage	-40...85 °C
Ambient air temperature for operation	-40...55 °C
IP degree of protection	IP20 conforming to EN/IEC 60529
Dielectric strength	2500 V

Socket

Socket with Mixed Contact Terminals and Connector

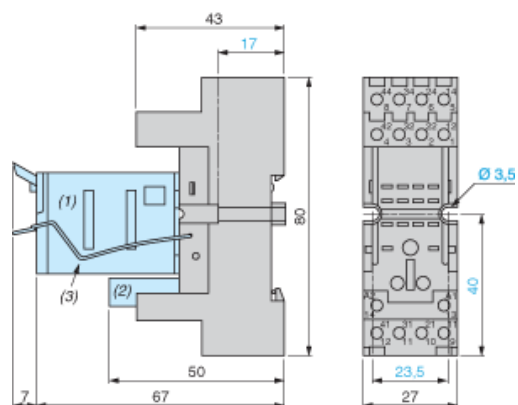

- 1 Relay
- 2 Protection Module
- 3 Carriage Stirrup