


Product availability : Non-Stock - Not normally stocked in distribution facility



Price* : 754.00 USD

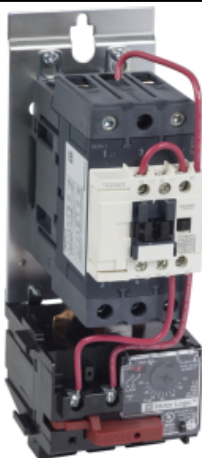

Main

Product	Starter
Range of product	TeSys N
Line Rated Current	45 A
Certifications	CE CSA UL listed
Control Circuit Type	Common control circuit
Enclosure Type	Not rated (open device)
Auxiliary Contacts	1 NO + 1 NC
Horsepower Rating	10 HP 200 V AC 15 HP 230 V AC 25 HP 460 V AC 25 HP 575 V AC
Number of Poles	3P
Phase	3 phases
System Voltage	600 V AC
NEMA Size	2
Control Circuit Voltage	120 V AC
Starter Type	Non reversing
Electrical Connection	Screw clamp terminals
Overload Type	Solid state Motor Logic class 10/20 15...45 A

Ordering and shipping details

Category	21198 - TESYS N STARTERS SIZES 00 - 2
Discount Schedule	CP1
GTIN	00785901958123
Nbr. of units in pkg.	1
Package weight(Lbs)	8.0999999999999996

Returnability	Y
---------------	---

Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including:
- - - - - Substance 1	Di(2-ethylhexyl)phthalate (DEHP), which is known to the State of California to cause cancer and birth defects or other reproductive harm.
- - - - - More information	For more information go to www.p65warnings.ca.gov