




# PNEUMATICS & FITTINGS

## PRV STATION AND PLUG VALVES, FILTER, CALIBRATION KIT

**MODELS K-332, FILN05, TOOL-95**

### DESCRIPTION

The **Model K-332** PRV station is a cartridge-style filter element that removes oil vapor, moisture, and dirt to one-micron size. The **Model K-332-B** assembly includes a wall mounting bracket, filter cartridge, pressure reducing valve, and three shut-off / bypass valves for uninterrupted filter servicing. This complete airflow station is designed for airflow rates and pressure regulation up to 8 scfm and 30 psig (200 kPa). The regulator is adjustable up to 35 psig (241 kPa). The K-332 has a one-year warranty.

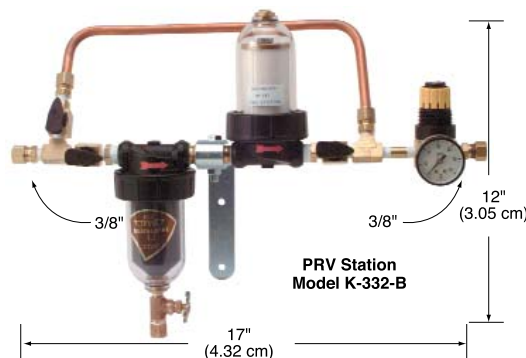

### ORDERING INFORMATION

MODEL	DESCRIPTION	WEIGHT lb (kg)
K-332	PRV station with filters	3.15 (1.43)
K-332-B	PRV station and bypass with three isolating plug valves	4.6 (2.1)
WXU-220	Replacement filter	1.0 (0.45)

### DESCRIPTION

The **Model FILN05** is a point-of-use pneumatic air filter. The Microfibre disposable filter unit consists of a HEPA Microflex™ filter tube permanently bonded into a sealed nylon casing. As the **Model FILN05** transparent filter shows signs of contamination, simply remove and replace.

NOTE: Not for use with synthetic lubricants.



FILN05

### ORDERING INFORMATION

MODEL	DESCRIPTION
FILN05	Inline disposable air filter

### SPECIFICATIONS

Connections	1/4" poly tube
Dimensions	2.75" length x 1" diameter
Ambient	32° to 200°F (0° to 93°C)
Filter	HEPA Microflex™
DOP efficiency	99.99%, 0.2 μm
Construction	Transparent nylon
Flow	1.4 scfm, 1.5 psid
Maximum pressure	100 psi at 100°F
Weight	0.3 oz (8.5 g)

### DESCRIPTION

The **TOOL 95-1** is a pneumatic control calibration kit. It includes gauges, wrenches, tees, screwdrivers and a squeeze-bulb pump. The **TOOL M-225** is a larger replacement squeeze bulb pump for higher air volumes.

Weight = 1 lb 4 oz

### ORDERING INFORMATION

MODEL	DESCRIPTION
TOOL 95-1	Pneumatic thermostat calibration kit
TOOL M-225	Large-capacity squeeze bulb pump



TOOL M-225