



## TR50VA001US

Transformer 50 VA, 120 to 24 Vac, Foot and Single Threaded Hub Mount

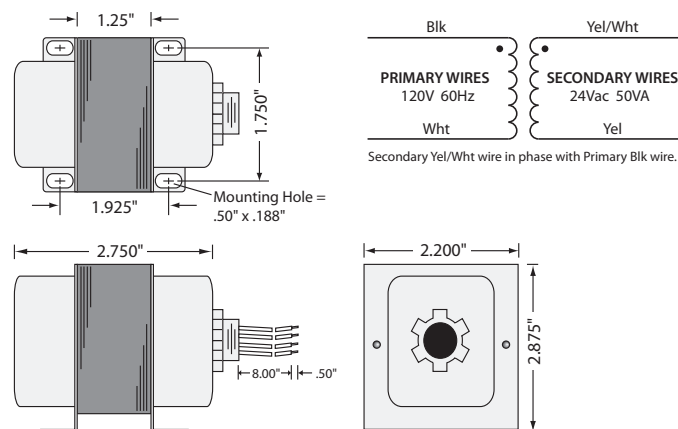

## Transformer

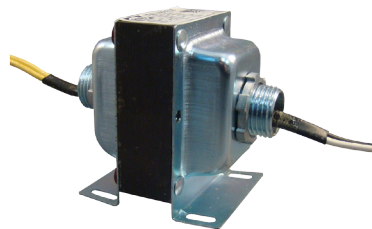

**Made in USA**  
Meets  
"Buy American"  
of ARRA 2009

## Specifications

**VA Rating:** 50  
**Frequency:** 50/60 Hz  
**Mounting:** Foot & Single Threaded Hub  
**Over Current Protection:** 3 Amp Fuse  
**Dimensions:** 2.875" x 2.200" x 2.750"  
 (w/ .500" NPT Hub)  
**Wire Length:** 8" Typical w/ .5" Strip  
**Operating Temperature:** -30 to 140° F  
**MTBF:** 100,000 Hours @ 77° F  
**Construction:** Split-Bobbin  
**Weight:** 2.14 lbs.  
**Approvals:** Class 2 UL5085-3 Listed, C-UL, CE, RoHS