



Honeywell Analytics
experts in gas detection



DESCRIPTION

The **Honeywell Analytics VA301C-DLC Gas Detection Controller** provides continuous monitoring of up to 96 inputs/outputs, on three channels, at distances up to 2000'. Modbus communication channels are included. The **VA301C-DLC** is pre-programmed at the factory, but menu driven changes can be made in the field. The **VA301C-DLC** allows monitoring of an entire network and will initiate an alarm or ventilation activation upon detection of a gas. One model is available with datalogging.

The **VA301C-DLC Gas Detection Controller** is designed to be used as part of a control system that helps to prevent the formation of a hazardous environment when properly installed and maintained.



VA301C-DLC



VA-301R-8

FEATURES

- Full array of visual indicators and audible alarm
- Multiple fully programmable alarm levels
- Programmable time delays
- Failure indicator
- Up to 96 transmitters and relay modules
- Up to 768 events
- Up to 128 zoning groups
- Graphic 122 x 32 dot-matrix display
- Datalogging available
- Programmable relay differential

7

GAS & SPECIALTY SENSORS

| SPECIFICATIONS | | | |
|-----------------------------------|---|------------------------------|--|
| Supply Voltage | | User Interface | |
| VA301C-DLC | 17-27 VAC @ 8.6 VA or 24-38 VDC @ 350 mA | Visual Indication | Dot-matrix display and keypad Blinking Green LED: Normal operation Red LED: Alarm Level 1, 2, and 3 Blinking Amber LED: Signal Tx Blinking Green LED: Signal Rx Yellow LED: Failure |
| VA301R | 17-27 VAC @ 8.6 VA or 24-38 VDC @ 250 mA | Operating Temperature | -4° to 122°F (-20° to 50°C) |
| Relay Output | 5A, 30 VDC or 250 VAC (resistive load) | Operating Humidity | 0% to 95% RH (non-condensing) |
| VA301C-DLC | 4 DPDT relays (alarms/fault), buzzer | Dimensions | |
| VA301R | 8 DPDT relays | VA301C-DLC | 8.0" H x 11.0" W x 2.7" D (20.3 x 28.0 x 7.0 cm) |
| Relay Setpoint | Multiple with high and low setpoints | VA301R | 8.0" H x 9.5" W x 2.5" D (20.3 x 24.4 x 5.7 cm) |
| Alarm Auditory Levels [Db] | 65 dba @ 3 ft (1m) | Weight | |
| Alarm Time Delay | 0, 30 sec, 45 sec, 1-99 minute before and after alarm | VA301C-DLC | 2.3 lb (1.0 Kg) |
| Network | Capacity: Up to 96 transmitters and 96 relay modules | VA301R | 3.0 lb (1.4 Kg) |
| Communication | Three Modbus zones | Approvals | CSA |
| Distance To Transmitters | 2000' (600m) maximum, 65 ft (20m) T-Tap, 130 ft (40m) total T-Tap, 2000 ft (600m) maximum | Warranty | 1 year |




GAS & SPECIALTY SENSORS

GAS DETECTION CONTROLLER

VA301C-DLC

WIRING

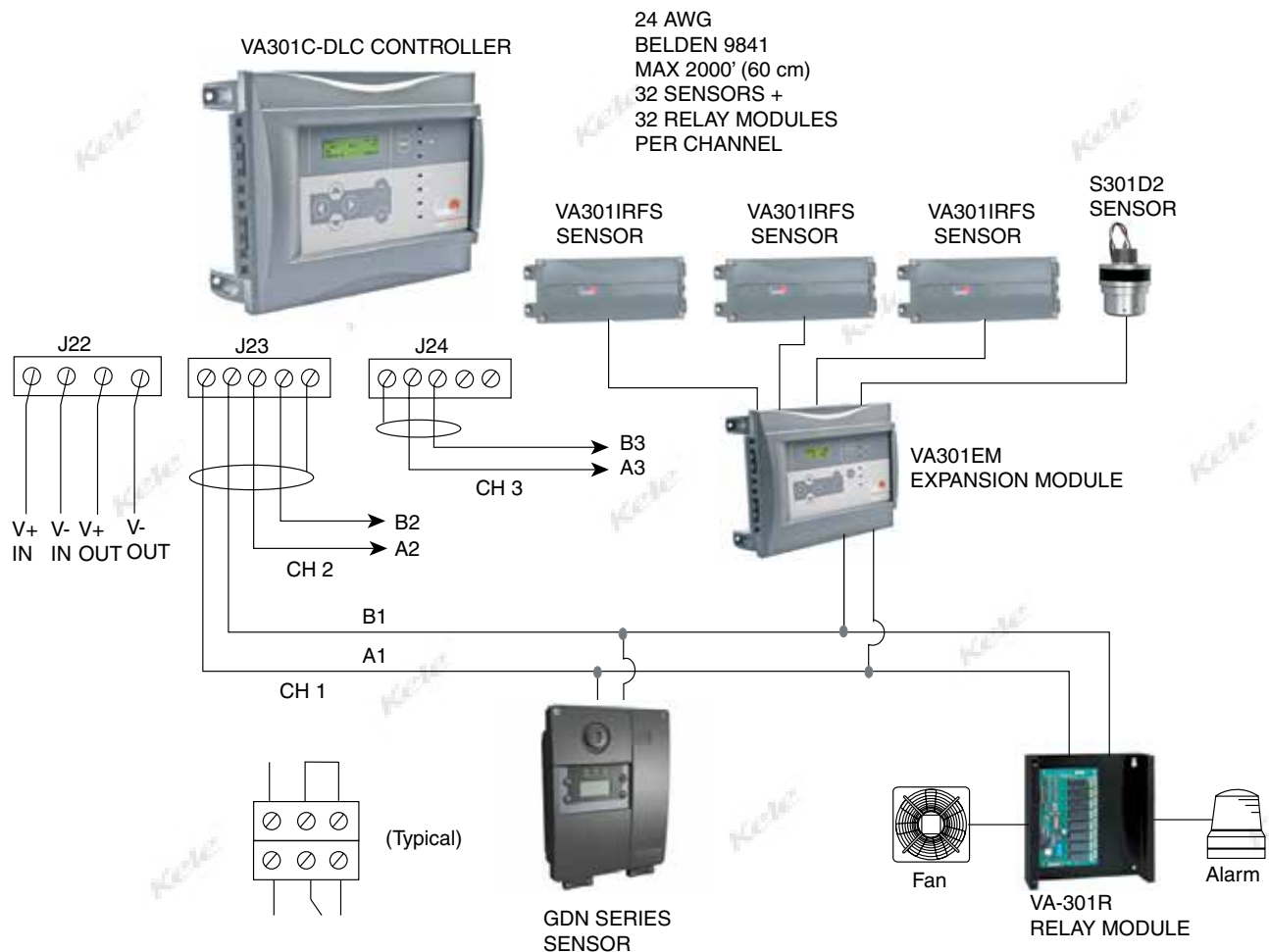

ORDERING INFORMATION

MODEL
VA301C-DLC
VA301R-8
VA301C

DESCRIPTION
Gas detection controller with datalogging
Eight-relay module
Gas detection controller

RELATED PRODUCTS

VA301EM
GDN Series

Gas detection expansion module
Network compatible gas detector

ACCESSORIES

691-K0A
DCP-1.5-W
DCPA-1.2

Control transformer, 120:24 VAC, 40 VA, Class 2
Power supply, 24 VAC IN to 24 VDC OUT
Power supply, 120 VAC IN to 24 VAC/24 VDC OUT